


TECHSPEC® 4mm Aperture, 25mm L High NA, Hexagonal Light Pipe

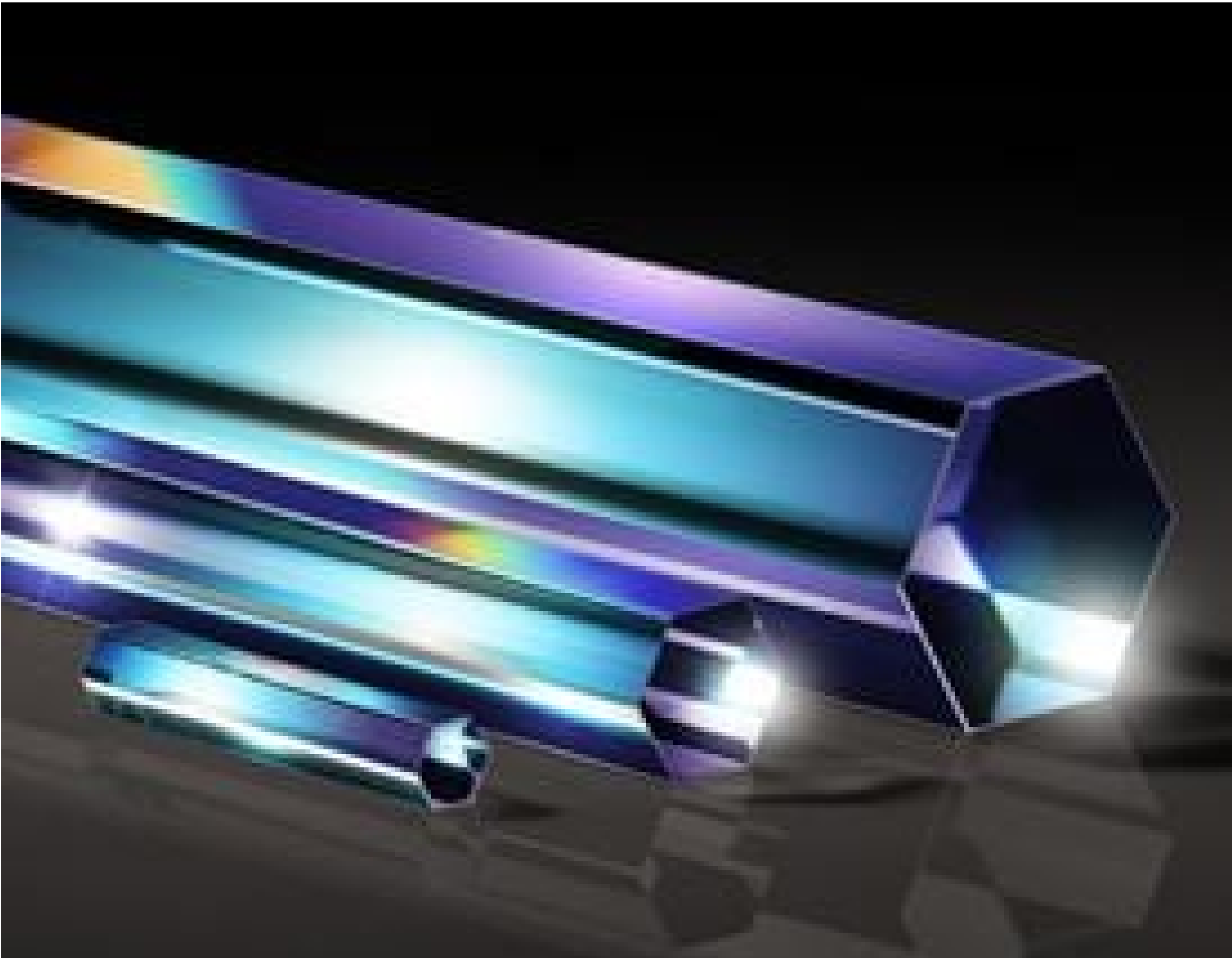

N-BK7 Light Pipe Homogenizing Rods



Stock **#63-082** 3-5 DAYS

− 1 +

A\$160.00

ADD TO CART

Qty 1-5
A\$160.00
Qty 6+
A\$128.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Uncoated

Substrate: ☐
[N-BK7](#)

Length (mm): 25.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 4.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: High
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 1λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View