


50 x 50mm, Blue 455nm, MicroBrite High Intensity Edge-Lit Backlights

See More by [Advanced Illumination](#)

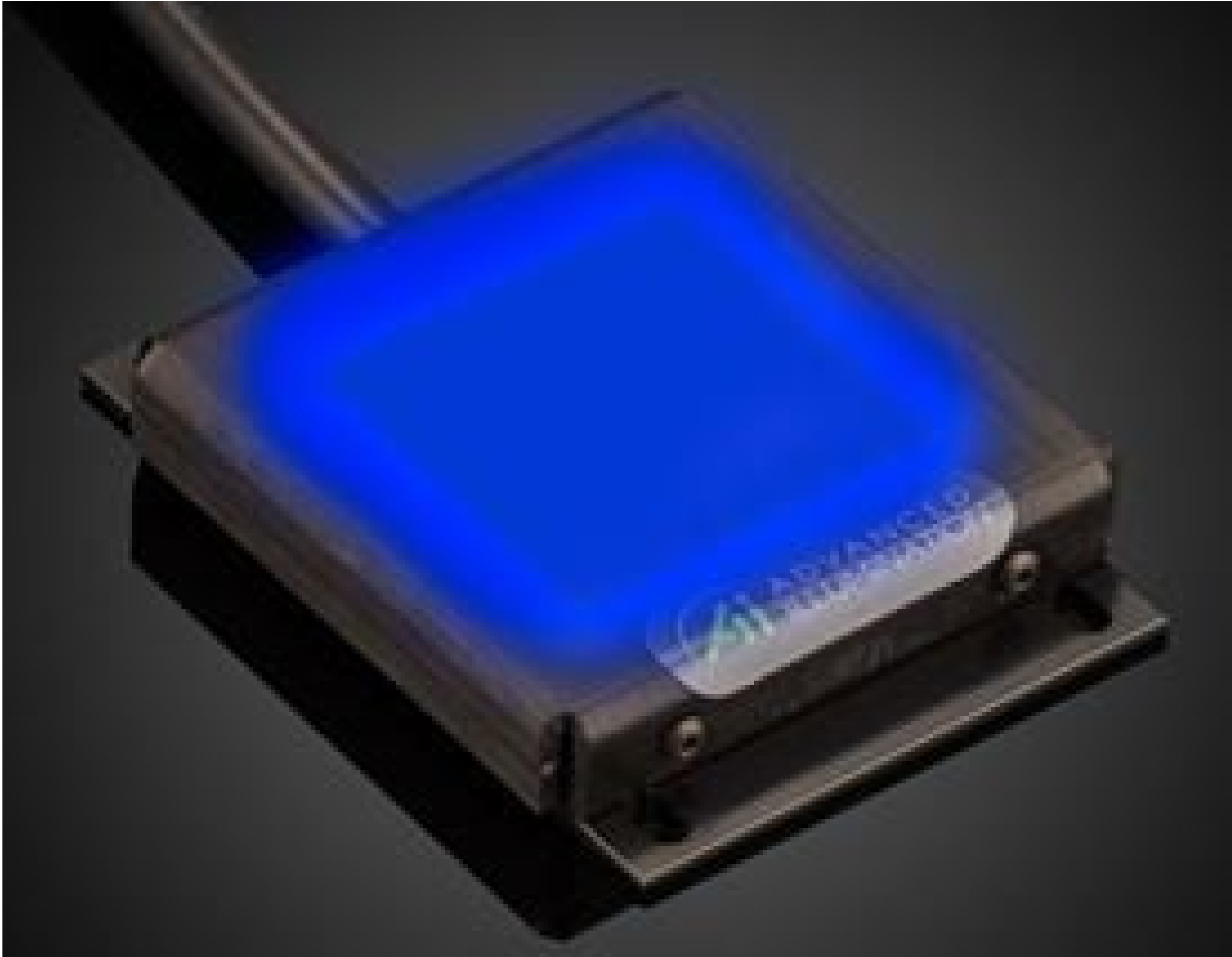

Stock #18-549 3-5 DAYS

⊖ 1 ⊕ **A\$1,337.60**

ADD TO CART

Qty 1+
A\$1,337.60

Volume Pricing
Request Quote

Get Product Downloads

Color: Blue
Input Voltage (V): 24V
Model Number: BT050050-455IC
Operating Temperature (°C): 0 - 60
Dimensions (mm): 70.3 x 54.71 x 11.33

Wavelength (nm): 455.00
Weight (g): 54.43
LED Lifetime (hours): 50,000
Active Area (inches): 1.40 x 1.35
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Backlight
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)