


**TECHSPEC®** 50 x 50mm Wire Grid Polarizing Film

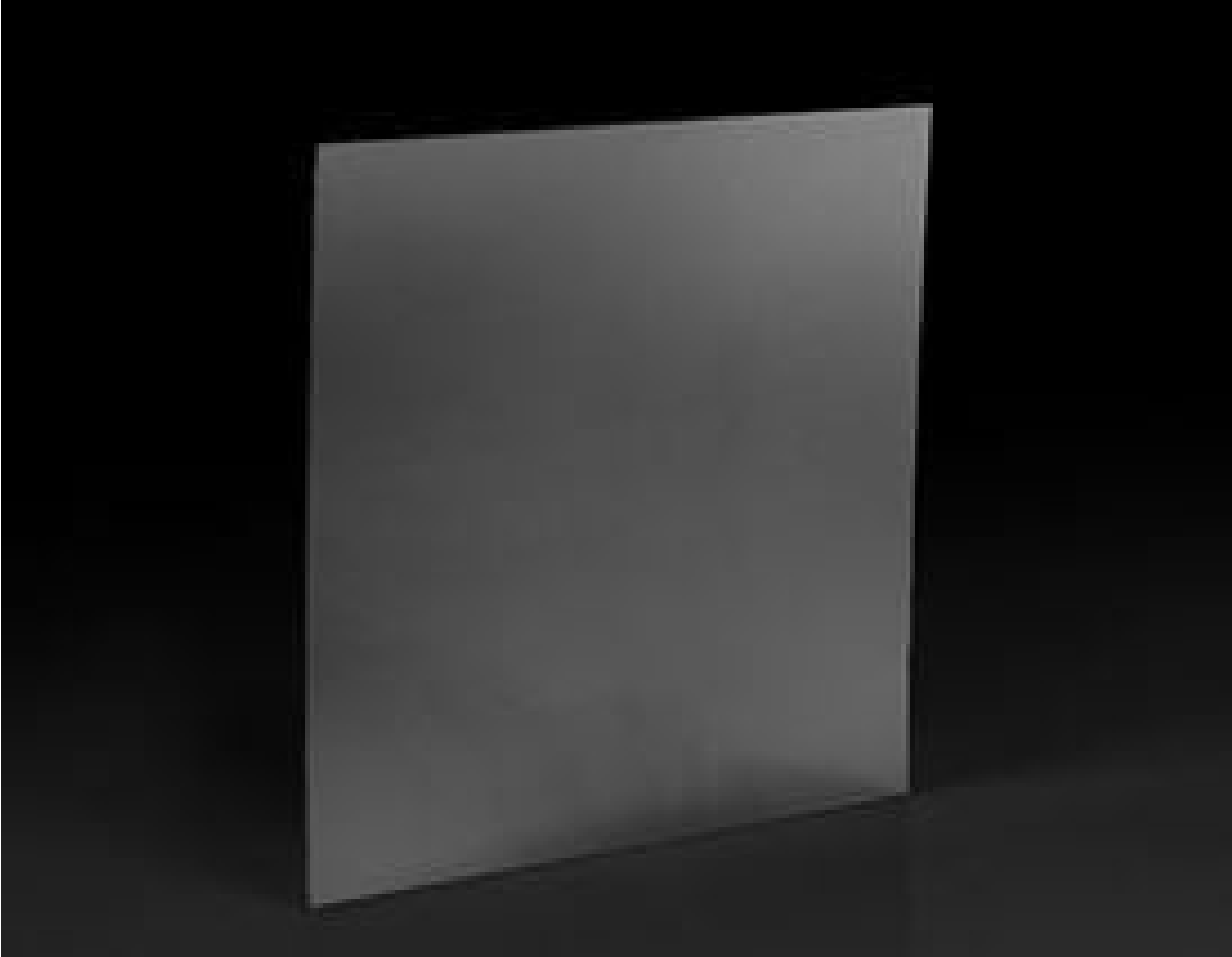

TECHSPEC® Wre Grid Polarizing Film

Stock **#33-083** CLEARANCE 3-5 DAYS

- 1 +

**A\$198.32**

ADD TO CART

Qty 1+

A\$198.32

Volume Pricing

[Request Quote](#)

Get Product Downloads



Angle of Incidence (°):  
0 - 45

Extinction Ratio:  
>4,250:1 @550nm

Substrate: [Aluminum Wires on TAC Film](#)

Length (mm):  
50.00

|                                                                                |
|--------------------------------------------------------------------------------|
| <b>Operating Temperature (°C):</b><br>60 Max @ 90% RH<br>105 in dry conditions |
| <b>Dimensions (mm):</b><br>50.0 x 50.0                                         |
| <b>Thickness (mm):</b><br>0.08                                                 |
| <b>Transmission (%):</b><br>85 (for p-polarized light @ 550nm)                 |
| <b>Type:</b><br>Linear Polarizer                                               |
| <b>Dimensional Tolerance (mm):</b><br>+0/-0.5                                  |
| <b>Construction:</b><br>Wire Grid                                              |
| <b>Wavelength Range (nm):</b><br>400 - 1200                                    |
| <b>Width (mm):</b><br>50.00                                                    |
| <b>Axis Orientation:</b><br>0° ± 1.5°, marked by Notch                         |

## Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 235:</b><br><a href="#">Contains SVHC(s)</a>      |