


# 50mm Diameter Laser Diode Mirror

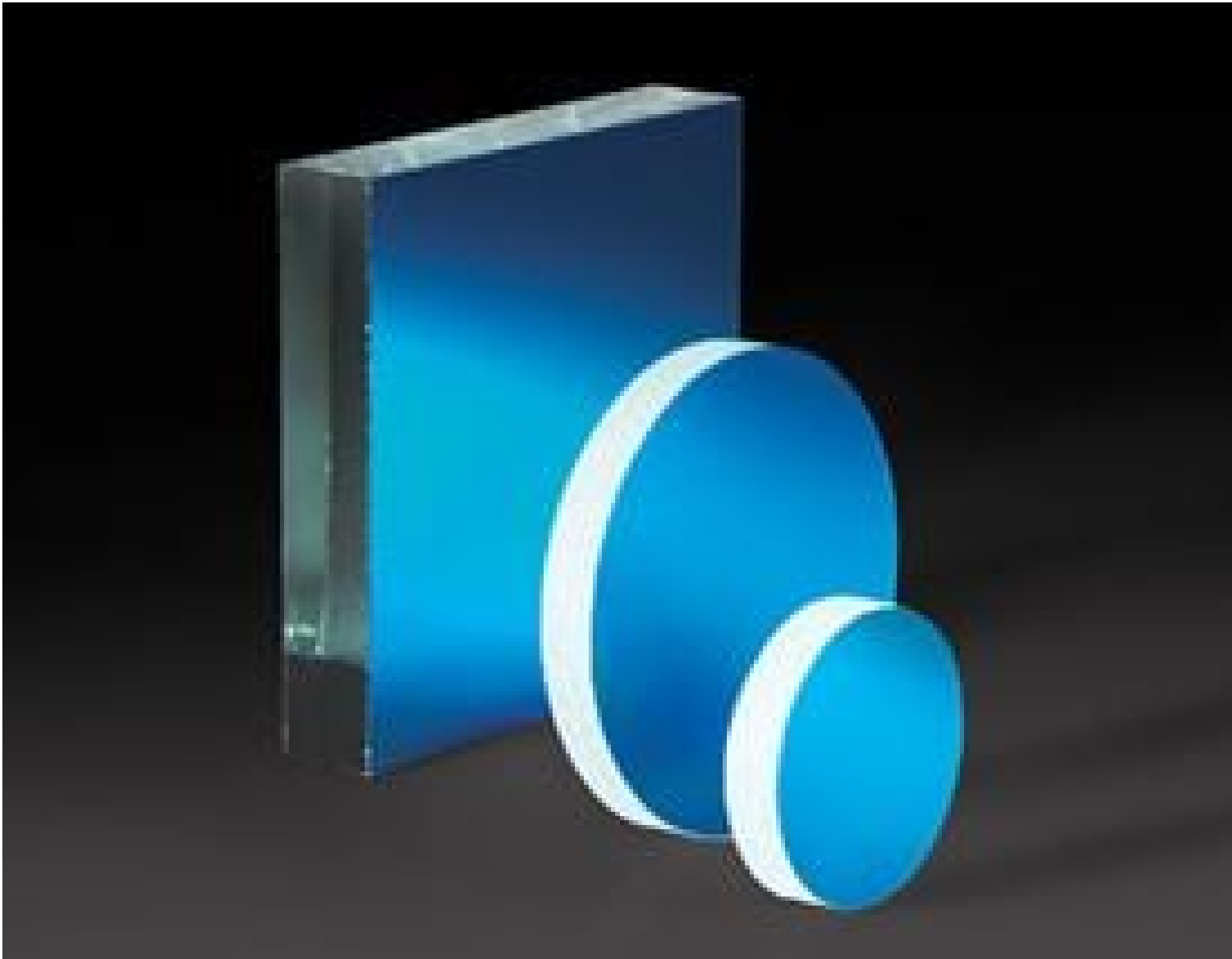

Stock #43-855 3-5 DAYS

-

1

+

A\$58.40

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| A\$58.40                      |
| Qty 11+                       |
| A\$46.40                      |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads

Diameter (mm):  
50.00 ±0.25

Substrate: ☐  
Float Glass

Surface Quality:  
80-50

Dimensional Tolerance (mm):  
±0.25

|                                                                |
|----------------------------------------------------------------|
| <b>Coating Specification:</b><br>R <sub>abs</sub> >97% @ 633nm |
| <b>Coating:</b><br>Dielectric Mirror (500-700nm)               |
| <b>Coating Type:</b><br>Dielectric                             |
| <b>Design Wavelength DWL (nm):</b><br>633                      |
| <b>Durability:</b><br>ML-C-48497A                              |
| <b>Thickness (mm):</b><br>3.00                                 |
| <b>Type:</b><br>Flat Mirror                                    |

## Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Compliant</a>             |

---