


50mm, IR 850nm, MicroBrite Brightfield Ring Light

See More by [Advanced Illumination](#)

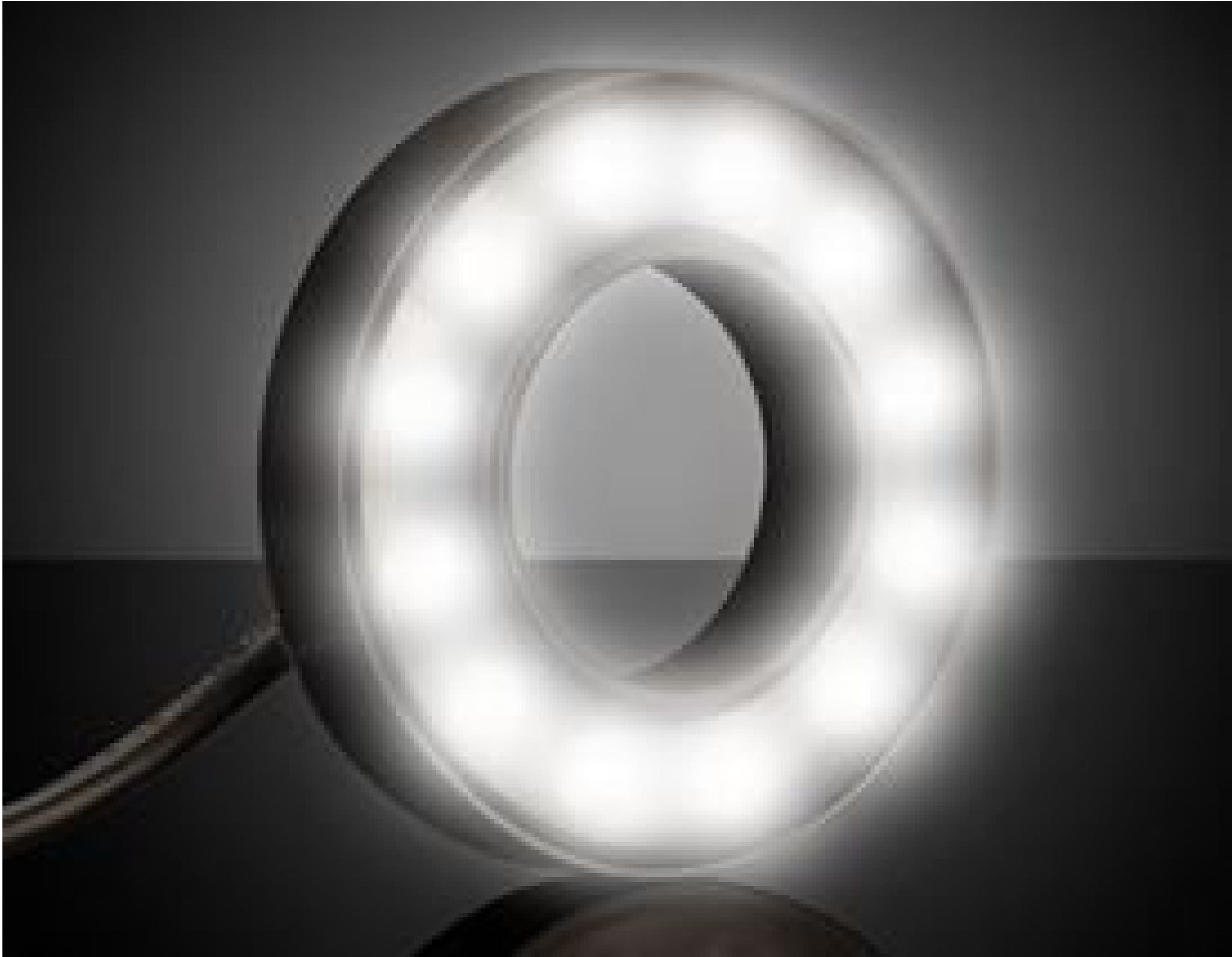

Stock #18-571 3-5 DAYS

⊖ 1 ⊕ **A\$1,304.00**

ADD TO CART

Qty 1+

A\$1,304.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Color:
IR

Height (mm):
19.09

Inner Diameter (mm):
50

Input Voltage (V):
24V

Model Number:
RL208M050850IC

Operating Temperature (°C): 0 - 60
Outer Diameter (mm): 95.34
Dimensions (mm): 50.00 x 95.34 x 19.09
Mounting Threads: M4 x4
Wavelength (nm): 850.00
Weight (g): 299
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: Not Available China: #66-855
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Maximum Input Current: 0.12A
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)