


TECHSPEC® 5mm Dia. x 10mm FL Uncoated, UV Plano-Convex Lens

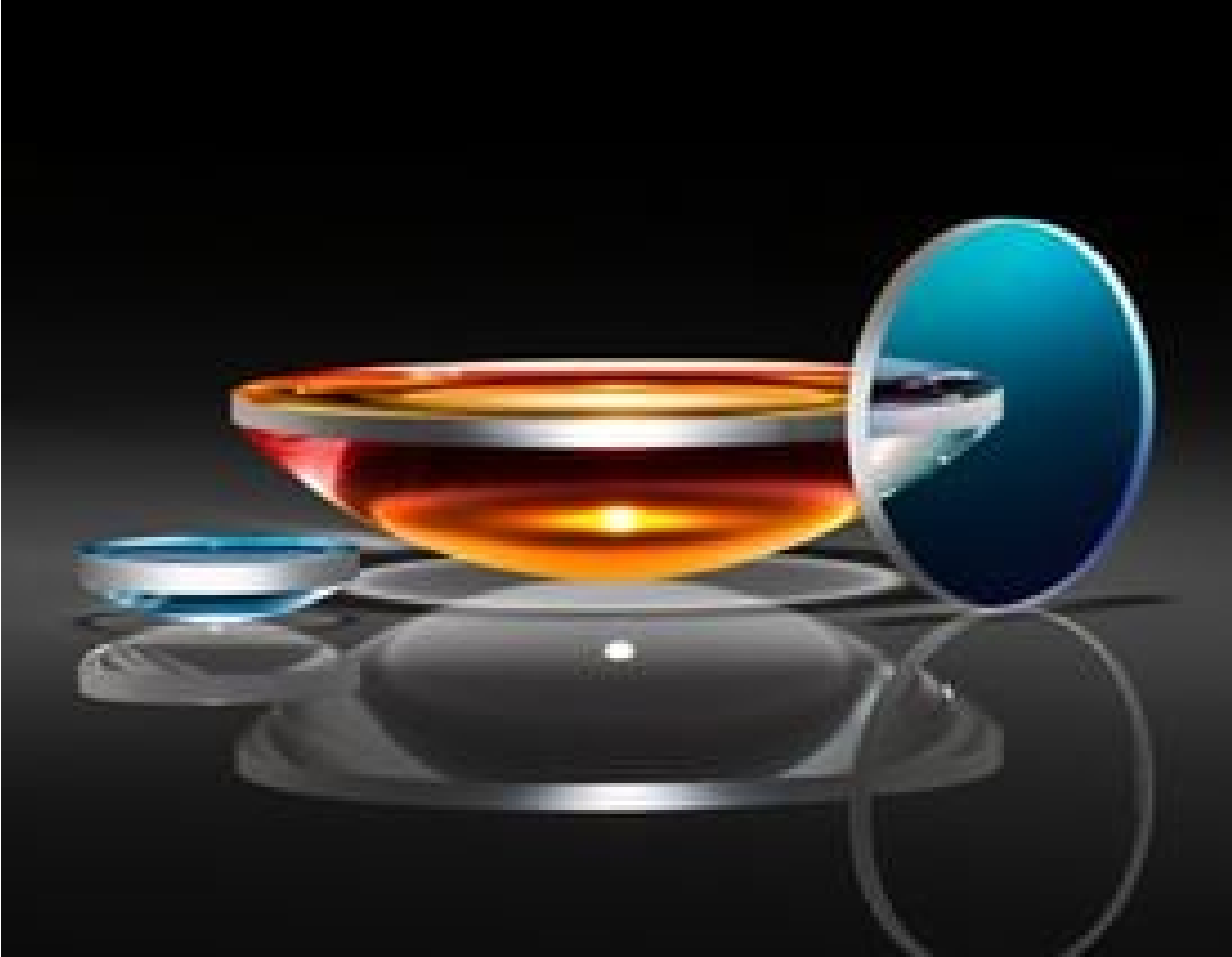

UV Fused Silica Plano-Convex (PCX) Lenses



Stock **#89-411** 3-5 DAYS

[Other Coating Options](#)

⊖ 1 ⊕

A\$184.00

ADD TO CART

Qty 1-5

A\$184.00

Qty 6+

A\$147.20

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
5.00 +0.0/-0.025

Effective Focal Length EFL (mm):

10.00 @ 587.6nm
Back Focal Length BFL (mm): 8.63
Coating: Uncoated
Substrate: Fused Silica (Corning 7980)
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Focal Length Tolerance (%): ±1
Centering (arcmin): <3
Center Thickness CT (mm): 2.00 ±0.05
Edge Thickness ET (mm): 1.26
Radius R ₁ (mm): 4.58
Clear Aperture CA (mm): 4.5
f/#: 2
Numerical Aperture NA: 0.25
Type: Plano-Convex Lens
Bevel: Protective bevel as needed
Wavelength Range (nm): 200 - 2200

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant