


5mm Diameter Laser Diode Mirror

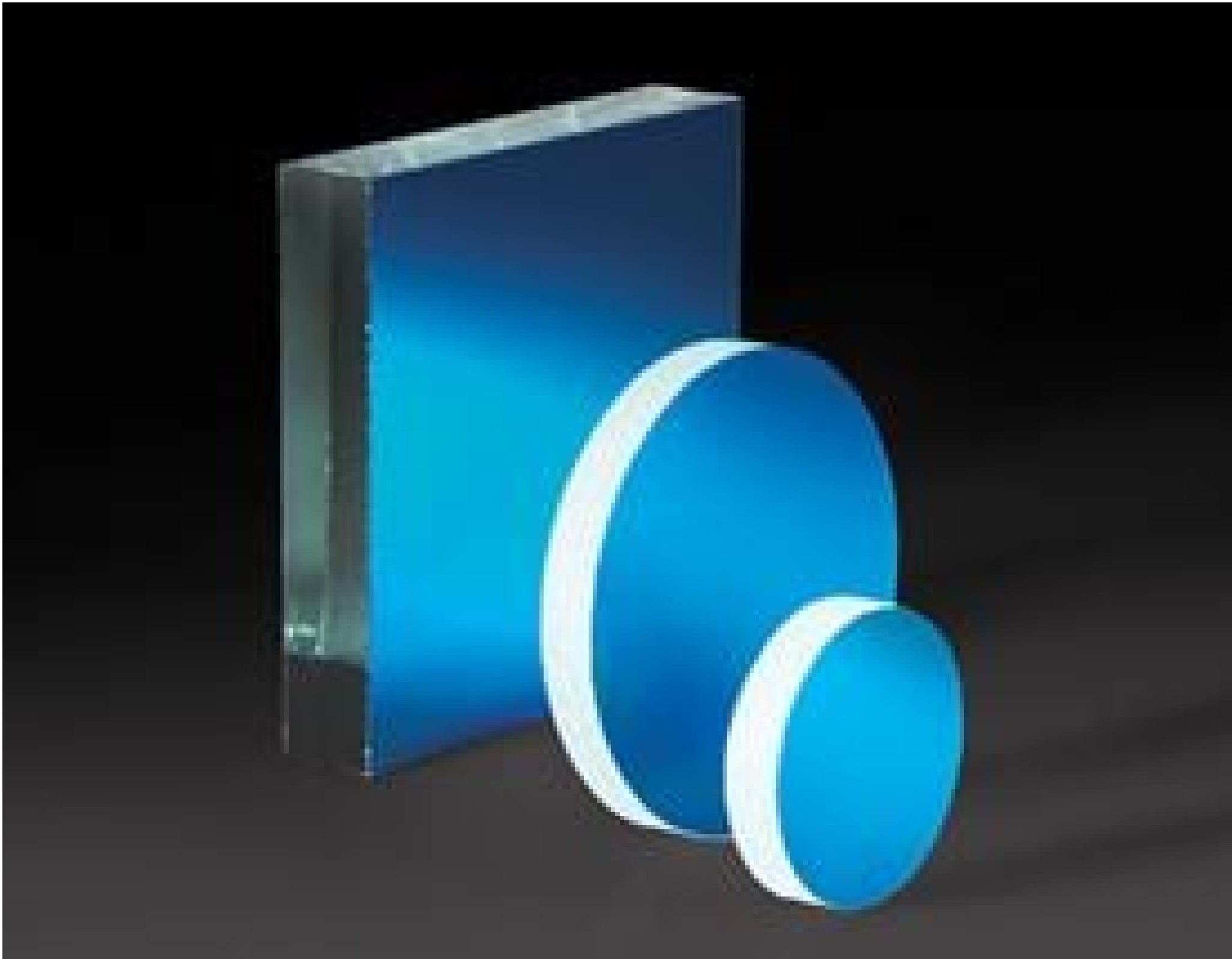

Stock **#46-617** 3-5 DAYS

- 1 +

A\$39.20

ADD TO CART

Qty 1-10
A\$39.20
Qty 11+
A\$30.40
Volume Pricing
Request Quote

Get Product Downloads

Diameter (mm):
5.00 ±0.25

Substrate: ☐
Float Glass

Surface Quality:
80-50

Dimensional Tolerance (mm):
±0.25

Coating Specification: R_{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 3.00
Type: Flat Mirror

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant
