


# 5mW, 635nm Laser Bat Power ZAT, 60° X-Hair

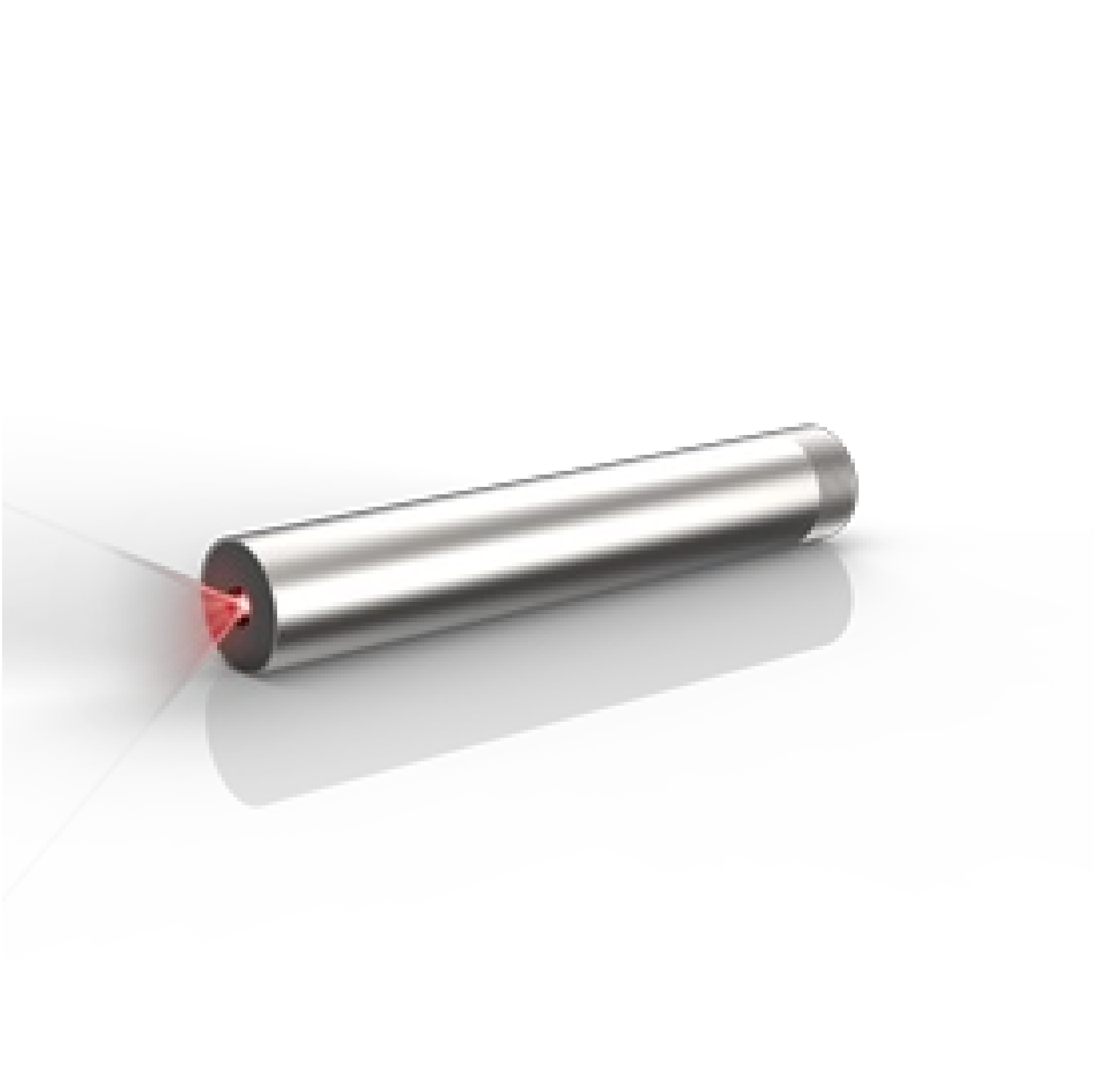

Stock **#19-540** [CONTACT US](#)

-

1

+

A\$480.00

ADD TO CART

|           |
|-----------|
| Qty 1-9   |
| A\$480.00 |

|           |
|-----------|
| Qty 10+   |
| A\$432.00 |

Volume Pricing

Get Product Downloads



**Output Power (mW):**  
5

**Wavelength (nm):**  
635.00

**Weight (g):**  
162

**Power Requirement:**  
1 AA Battery (Not Included)

**Style:**  
Crosshair

**Output Type:**  
Free Space

**Laser Class - CDRH:**  
1M

**Color:**  
Red

**Fan Angle (°):**  
60.00

**Focus Range:**  
Up to 1,500mm

**Length (mm):**  
124.00

**Environmental Rating:**  
IP40

Regulatory Compliance

**RoHS:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)