


[See all 1 Products in Family](#)

## 5mW, 635nm Laser Bat Power ZAT, 60° X-Hair (Recertified 05-P)

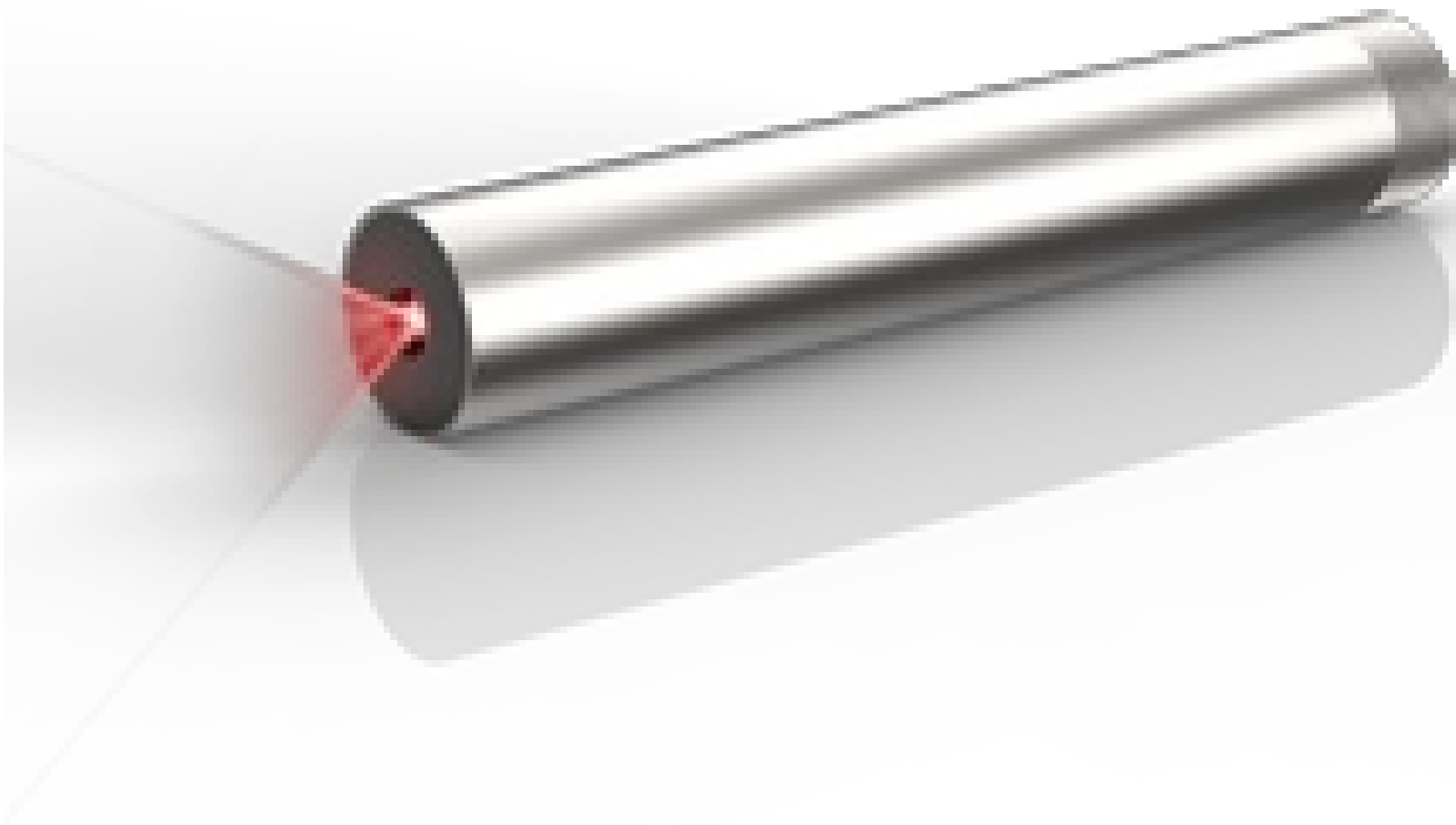

Stock #19-540-RCD-05P **RECERTIFIED** 1 In Stock

- 1 + A\$429.<sup>92</sup>

**ADD TO CART**

### Volume Pricing

Qty 1+	A\$429.92 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads



## General

Crosshair **Style:**  
1M **Laser Class - CDRH:**

## Physical & Mechanical Properties

162 **Weight (g):**  
124.00 **Length (mm):**

## Optical Properties

635.00 **Wavelength (nm):**  
Red **Color:**  
60.00 **Fan Angle (°):**  
Up to 1,500mm **Focus Range (mm):**

## Electrical

5 **Output Power (mW):**

## Hardware & Interface Connectivity

1 AA Battery (Not Included) **Power Requirement:**  
Free Space **Output Type:**

## Environmental & Durability Factors

IP40 **Environmental Rating:**

## Regulatory Compliance

[View](#) **Certificate of Conformance:**

## Product Details

- Bright Red 635nm Wavelength
- Line, Crosshair, or Dot Projection
- Battery Powered Operation with a Fixed Focus
- Sturdy, Metal Housing

Z-Laser ZAT Battery Powered Lasers are ideal for positioning and alignment applications. Their battery powered design provides maneuverability by removing the need for a fixed power supply. IP40 rated, shock proof, and vibration proof with a sturdy, metal housing makes these lasers excellent for harsh environments and repeated use. Z-Laser ZAT Battery Powered Lasers are suitable for use in industrial environments such as Automotive, Paper, Wood, Ceramic, and Metal. Available with 1 or 5mW output powers, the lasers utilize one AA battery (not included) ensuring easy maintenance and an extended lifetime.