


TECHSPEC® 6 x 8.5mm Enhanced Aluminum, 4-6λ Mirror

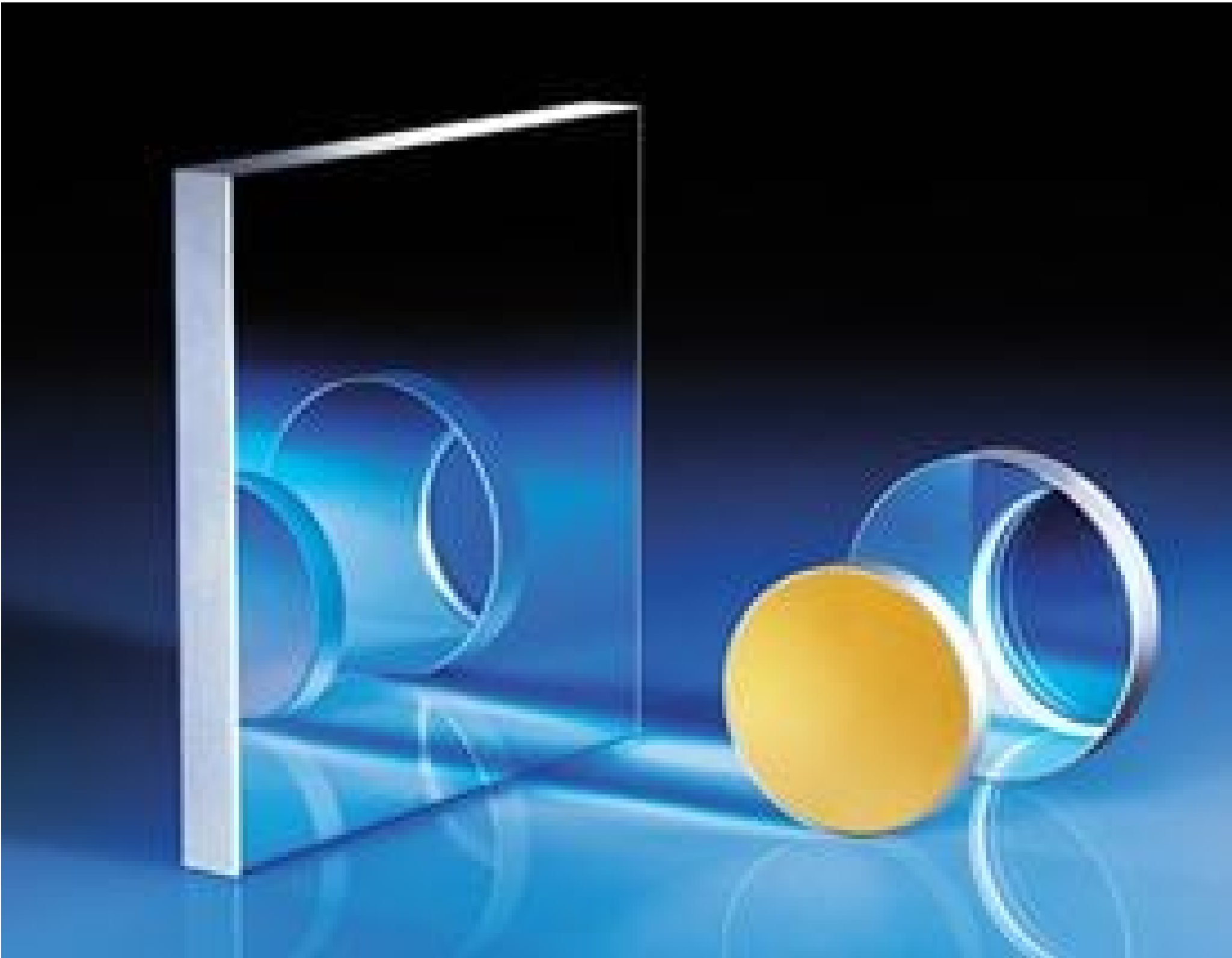

Stock **#43-867** 3-5 DAYS

- 1 +

A\$38.40

ADD TO CART

Qty 1-5

A\$38.40

Qty 6+

A\$29.60

Volume Pricing

[Request Quote](#)

Get Product Downloads

Surface Flatness (P-V):
4 - 6λ

Substrate: ☐
Float Glass

Surface Quality:
60-40

Dimensions (mm):
6.0 x 8.5

Dimensional Tolerance (mm): ±0.25
Coating Specification: R_{avg} ≥95% @450 - 650nm @45°
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture CA (mm): 5.00 x 7.50
Edges: Seamed, 0.5mm Maximum Edge Chip
Thickness (mm): 2.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 8.50
Width (mm): 6.00
Damage Threshold, By Design: 0.2 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant