


TECHSPEC® 6mm Aperture x 150mm L Low NA, Fused Silica Light Pipe

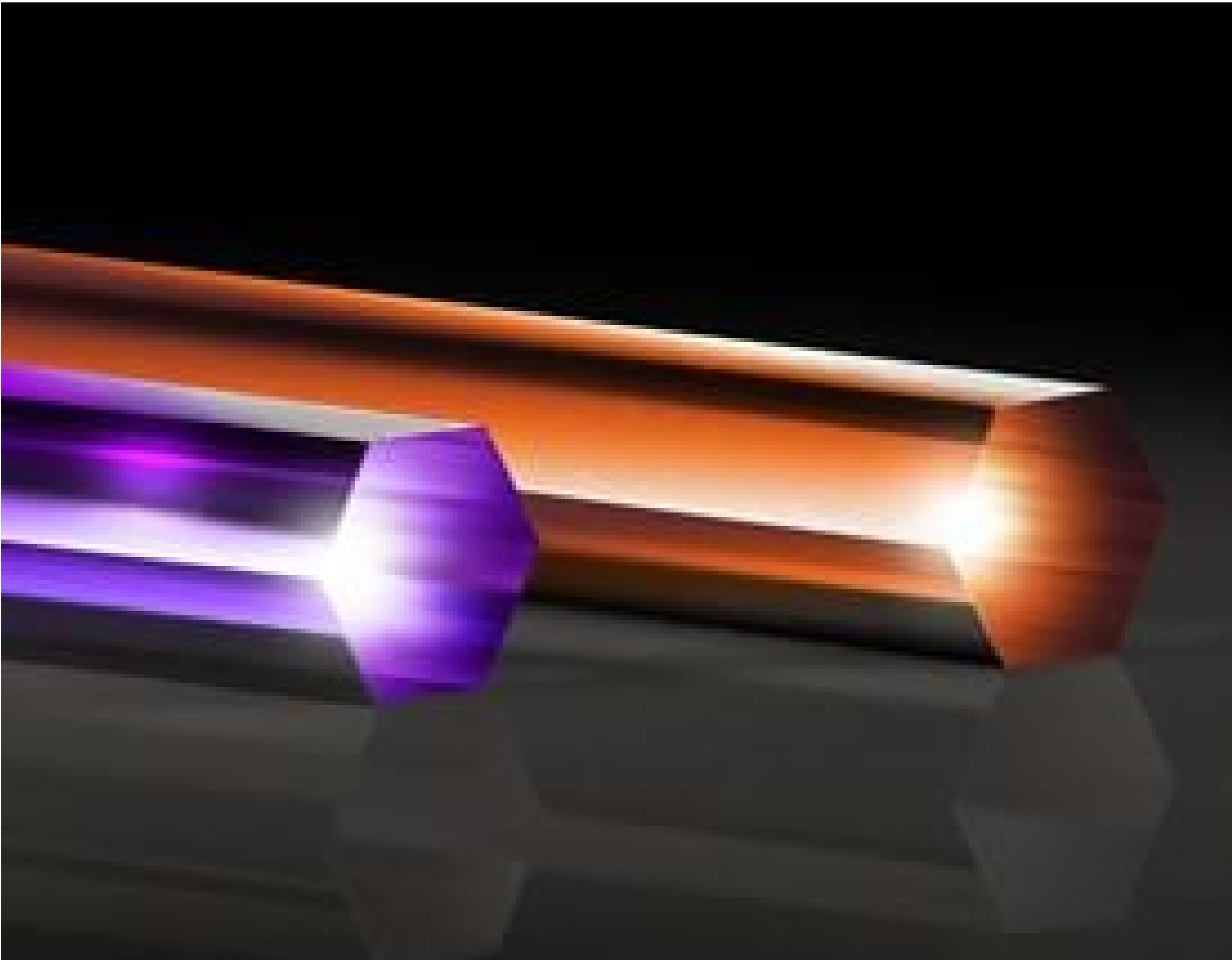

Fused Silica Light Pipe Homogenizing Rods



Stock **#65-835** 3-5 DAYS

- 1 +

A\$416.00

ADD TO CART

Qty 1-5
A\$416.00
Qty 6+
A\$332.80
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Uncoated

Substrate: [Fused Silica](#) (Corning 7980)

Length (mm): 150.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 6.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 200 - 2200
Surface Flatness (P-V): 1λ
#Sorting: 43.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View