


TECHSPEC®

70mm, Center Drive, Thru-Hole, English Extended Micrometer

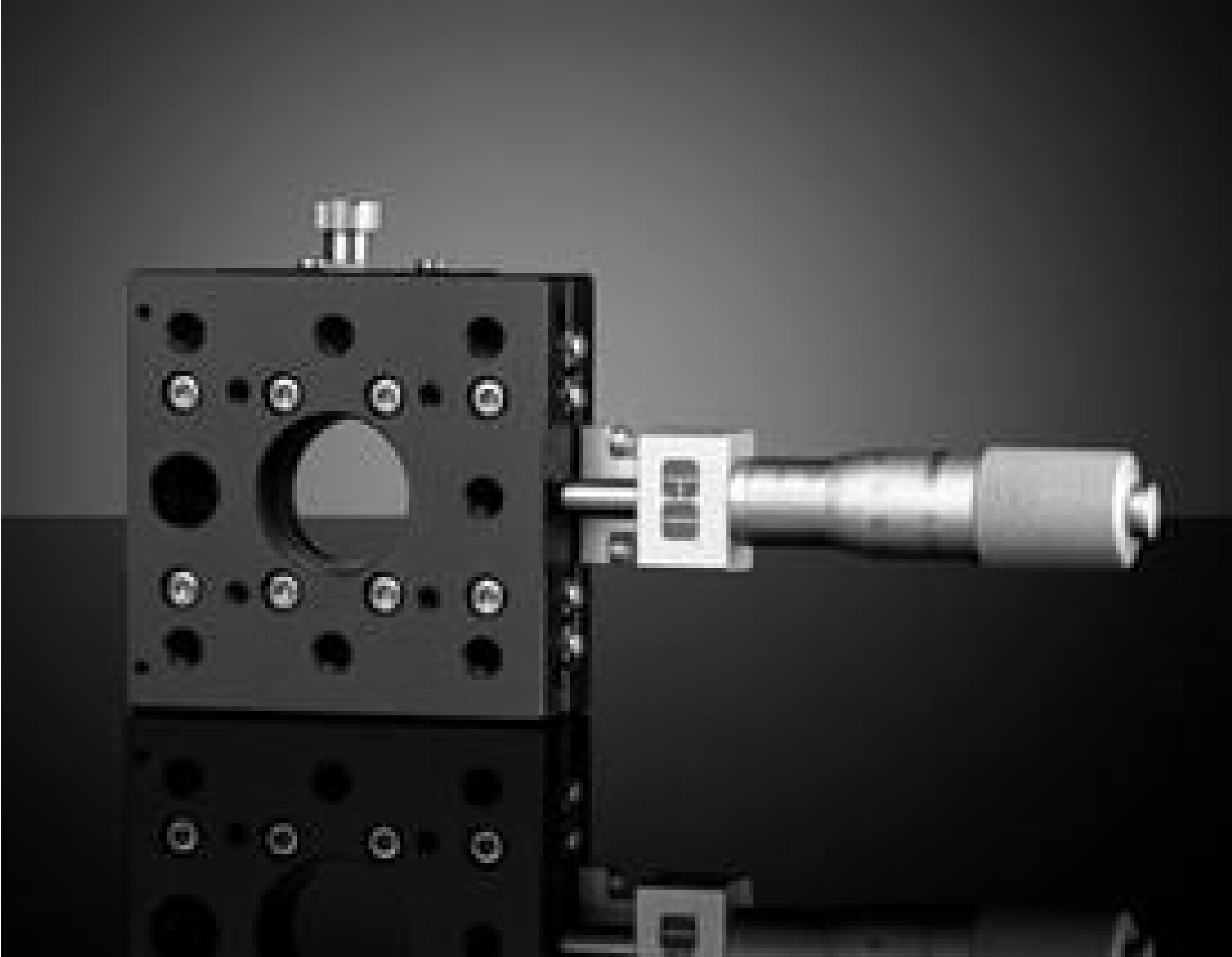

Stock #66-440

3-5 DAYS

-

1

+

A\$841.60

ADD TO CART

Qty 1-2

A\$841.60

Qty 3+

A\$733.92

Volume Pricing

[Request Quote](#)

Get Product Downloads

Type of Movement:

Linear (X)

Guide System:

Crossed Roller Bearing

Type of Drive:

English Micrometer

Drive Orientation:

Center Drive

Type: English
Stage Size (mm): 70 x 70
Travel (inches): 1
Center Hole: 1" x 32 TPI
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.635
Load Capacity (kg): 8
Mounting Threads: (1) 1" x 32, (7) 1/4-20, (4) 6-32
Stage Size (inches): 2.75 x 2.75
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)
