


## 76.2 x 76.2 x 3mm High Efficiency Window

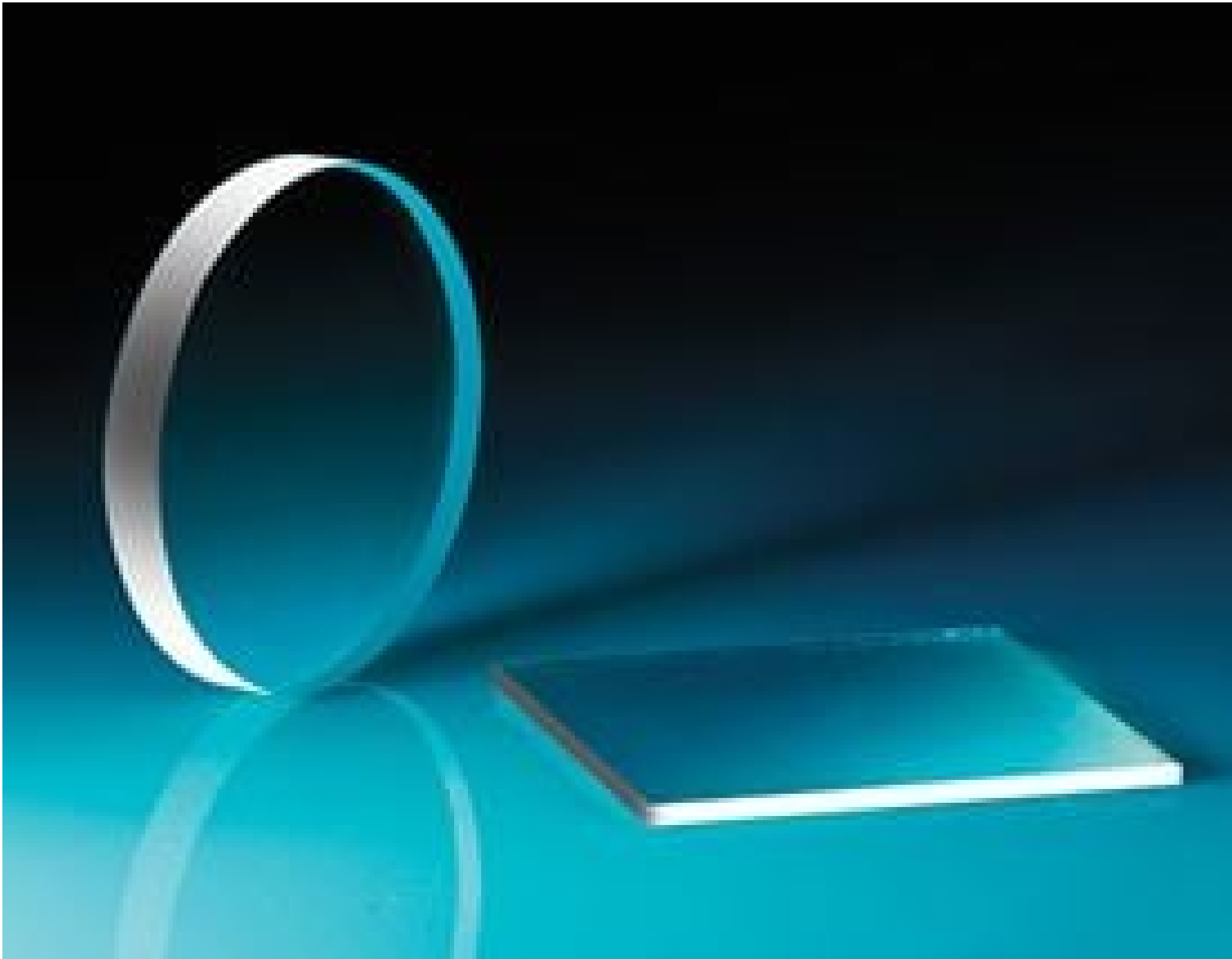

Stock **#46-101** 3-5 DAYS

⊖ 1 ⊕

**A\$46.40**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| A\$46.40                      |
| Qty 6+                        |
| A\$37.20                      |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads



Angle of Incidence (°):  
0

Bevel:  
Protective as needed

Clear Aperture (%):  
≥90

Clear Aperture CA (mm):

|                                                                       |
|-----------------------------------------------------------------------|
| 68.58 x 68.58                                                         |
| <b>Dimensions (mm):</b><br>76.20 x 76.20                              |
| <b>Thickness (mm):</b><br>3.00 ±0.25                                  |
| <b>Coating:</b><br>BBAR (425-700nm)                                   |
| <b>Coating Specification:</b><br>R <sub>avg</sub> ≤0.5% @ 425 - 700nm |
| <b>Edges:</b><br>Seamed                                               |
| <b>Substrate:</b><br>Float Glass                                      |
| <b>Surface Quality:</b><br>80-50                                      |
| <b>Transmission (%):</b><br>95.6 Average (typical)                    |
| <b>Type:</b><br>Protective Window                                     |
| <b>Wavelength Range (nm):</b><br>425 - 700                            |
| <b>Length (mm):</b><br>76.20                                          |
| <b>Width (mm):</b><br>76.20                                           |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Compliant</a>             |