


830 Grooves, 30mm Square, 800nm NIR Ruled Grating

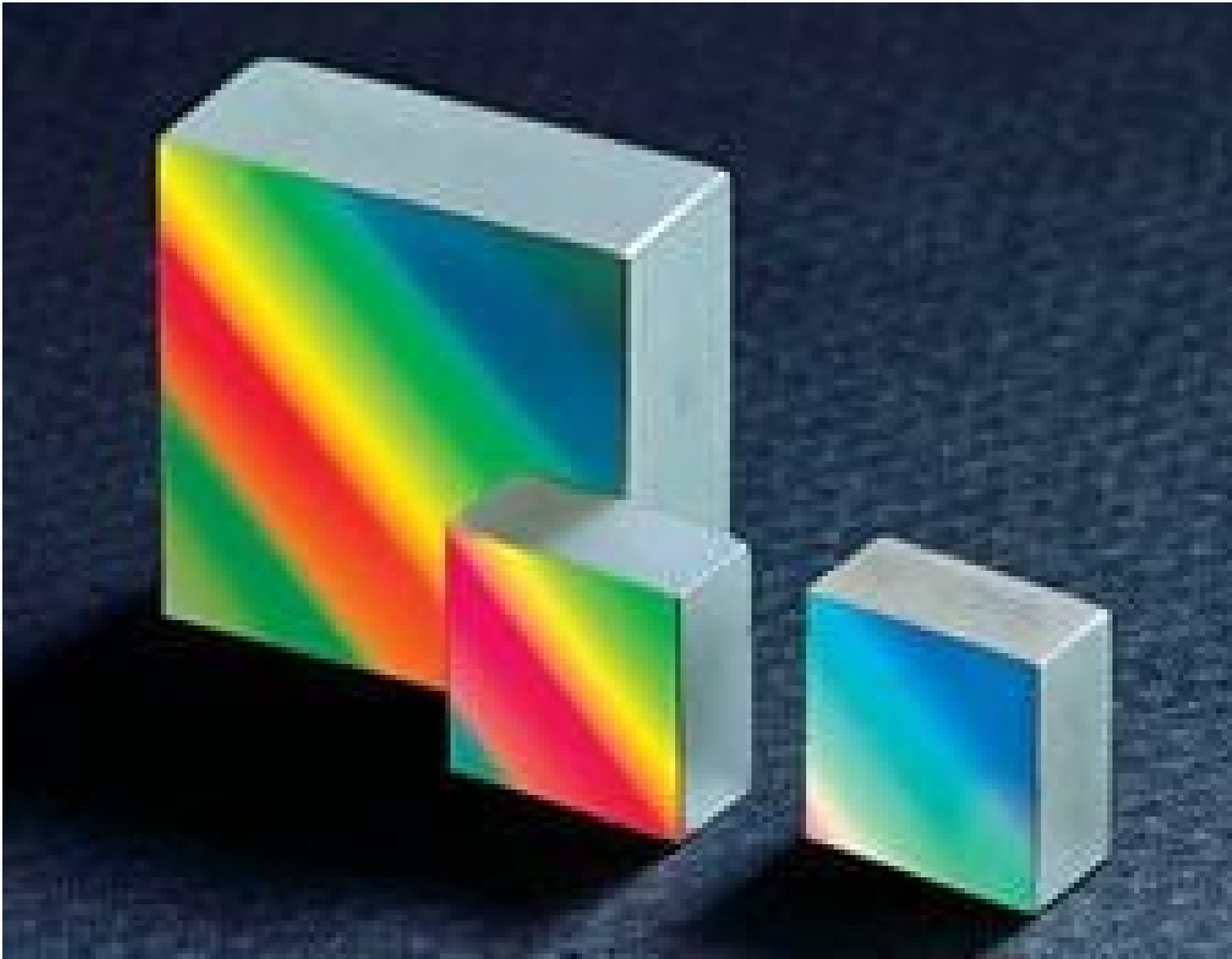

Stock #55-262 3-5 DAYS

- 1 + **A\$312.00**

ADD TO CART

Qty 1+
A\$312.00

Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
830

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
800

Blaze Angle (°):
19.38

Dimensions (mm):

30.0 x 30.0 ±0.5
Clear Aperture (%) : 90
Coating : Bare Gold
Construction : Ruled Grating
Direction of Grooves : Parallel to Short Dimension
Length (mm) : 30.00
Substrate : ☐ Float Glass
Thickness (mm) : 9.50 ±0.5
Type : Reflective Diffraction Grating
Width (mm) : 30.00
Alignment of Grooves to Edge (°) : ±0.5

Regulatory Compliance

RoHS 2015 : Compliant
Reach 219 : Compliant
Certificate of Conformance : View