 



# Hoya B370 (UV-VIS) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

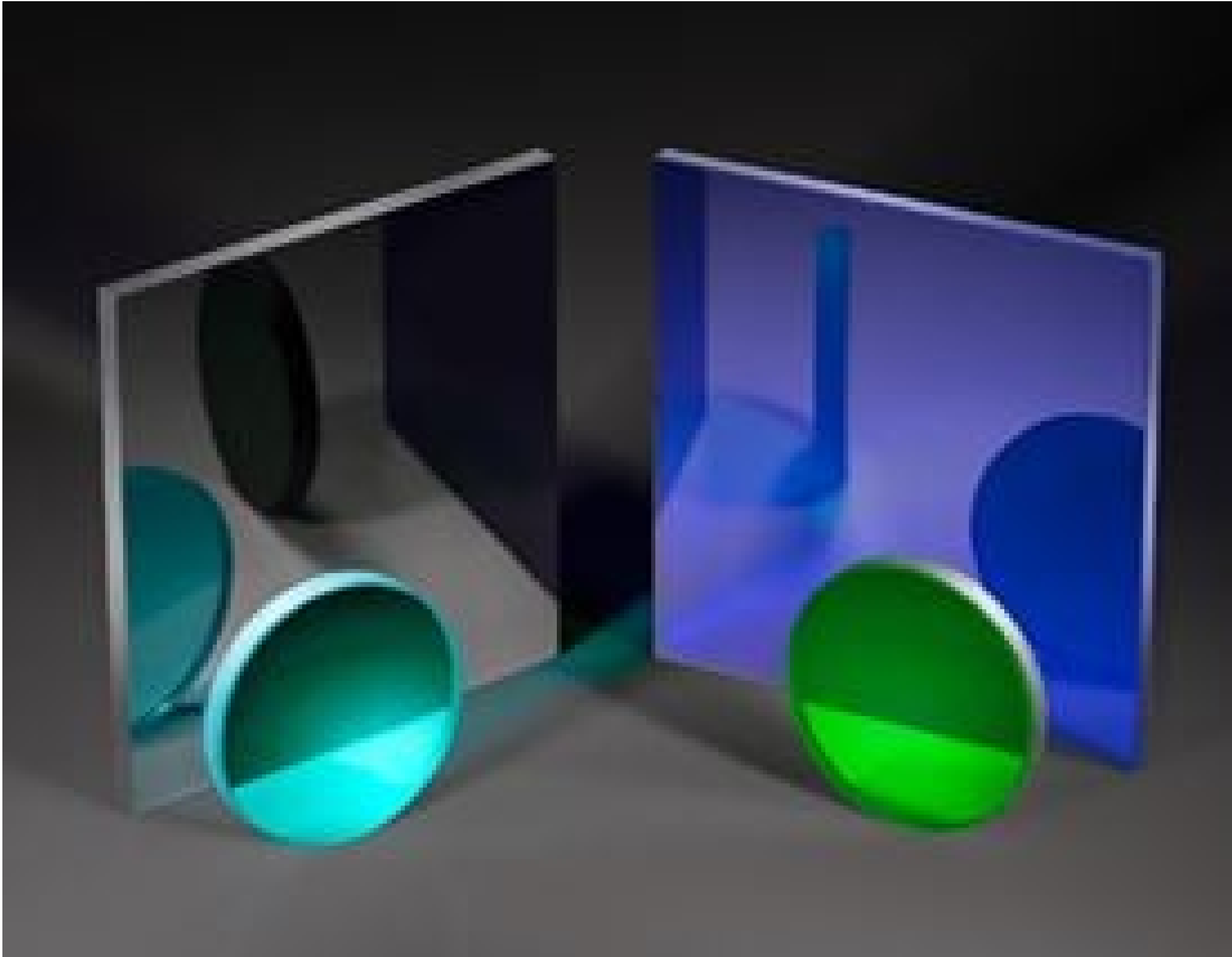

Stock **#48-639** [CONTACT US](#)

-

1

+

A\$172.80

ADD TO CART

Qty 1-10

A\$172.80

Qty 11+

A\$153.60

Volume Pricing

[Request Quote](#)

Get Product Downloads



**Dimensions (mm):**  
50.8 x 50.8

**Center Wavelength CWL (nm):**  
370.00

|                                                             |
|-------------------------------------------------------------|
| <b>Density (g/cm³):</b><br>2.36                             |
| <b>Full Width-Half Max FWHM (nm):</b><br>100.00             |
| <b>Glass/Filter Number:</b><br><a href="#">Hoya B370</a>    |
| <b>Substrate:</b> <input type="checkbox"/><br>Colored Glass |
| <b>Length (mm):</b><br>50.80                                |
| <b>Coating:</b><br>Uncoated                                 |
| <b>Color:</b><br>Blue-Violet                                |
| <b>Surface Quality:</b><br>60-40                            |
| <b>Thickness (mm):</b><br>2.50                              |
| <b>Thickness Tolerance (mm):</b><br>±0.2                    |
| <b>Type:</b><br>Bandpass Filter                             |
| <b>Wavelength:</b><br>UV-VIS                                |
| <b>Width (mm):</b><br>50.80                                 |
| <b>Parallelism (arcmin):</b><br>≤2                          |
| <b>Dimensional Tolerance (mm):</b><br>+0/-0.25              |

## Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Exempt</a>                |
| <b>Reach 224:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

---