


Blue Enhanced Response, 100.0mm², Silicon Detector

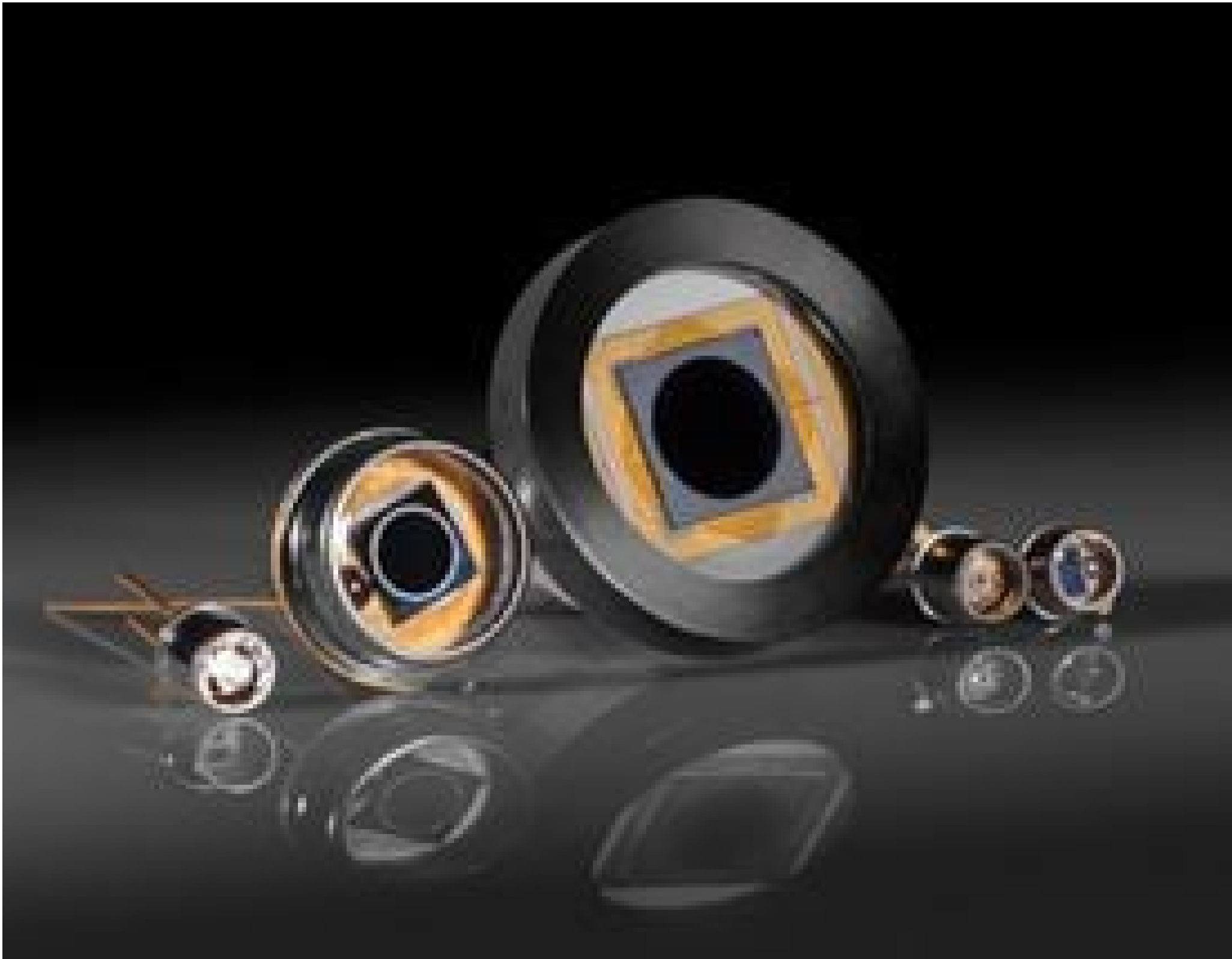

Silicon Photodiodes

Stock **#53-379** 3-5 DAYS



1



A\$216.00

ADD TO CART

Qty 1-4

A\$216.00

Qty 5+

A\$192.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Operating Temperature (°C):
-10 to 60

Type:
Unbiased

Typical Applications:
Low light levels, wide spectral bandwidth response

Terminal Capacitance (pF):

8800 @ 0 V
Rise Time (μs): 2.0 @ 0 V/50 Ω, 410nm
Saturation Current, I_{sat} (mA): 10.0
Responsivity @ 410nm (AW): 0.2
Active Area (mm²): 100.0
Noise Equivalent Power NEP (W/ Hz^{1/2}): 2.0 x 10 ⁻¹³
Detectivity (cmHz^{1/2}/W): 5.0 x 10 ¹² @ 0 V, 410nm
Shunt Resistance (MΩ): 10.00
Model Number: PIN-10DP/SB
Note: Blue Enhanced Response
Construction: PIN
Outer Diameter (inches): 0.98
Length of Leads (inches): BNC
Protective Window: Quartz
Package: BNC

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View