


Concentric Square Target

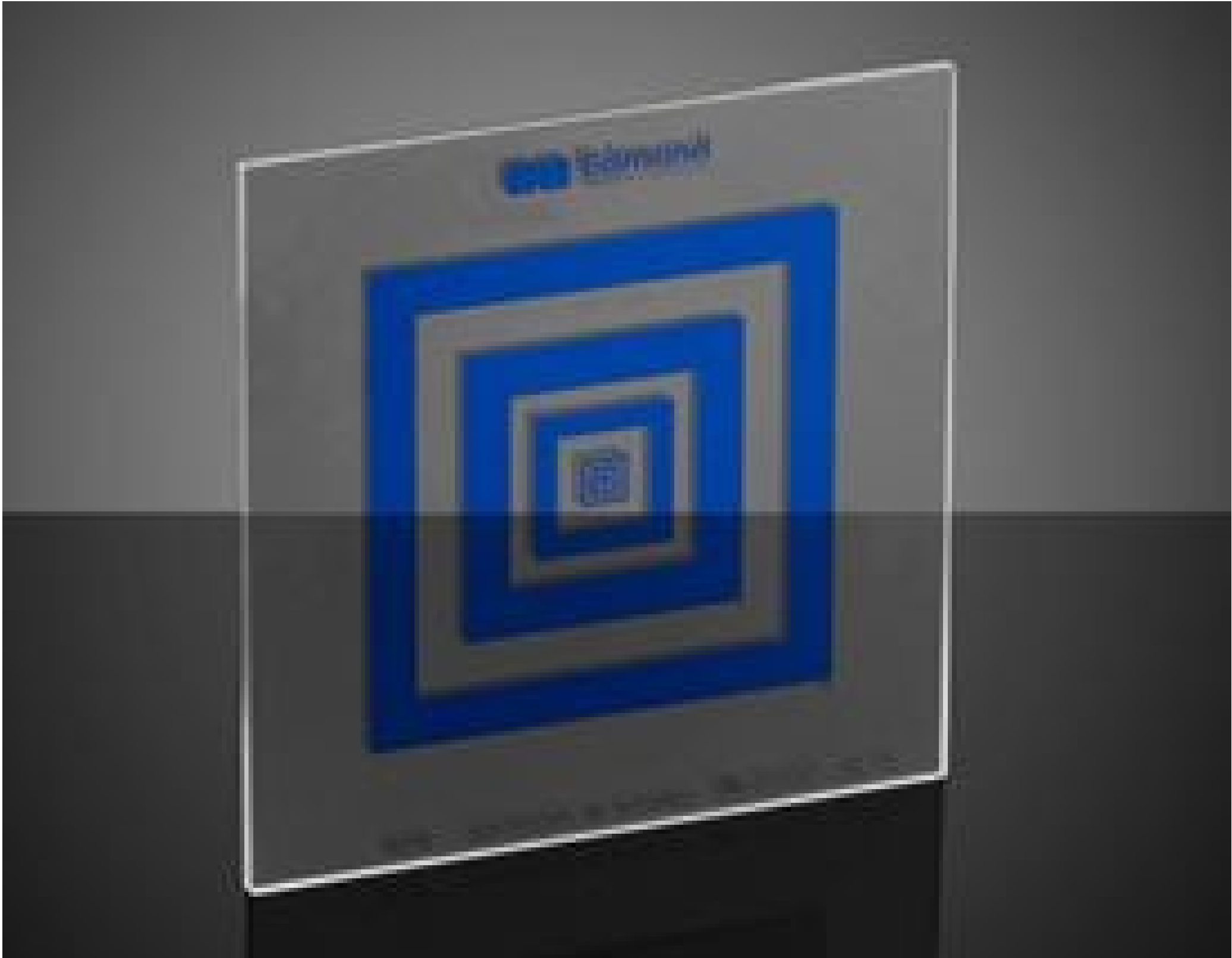

#46-248

Stock **#46-248** 9 In Stock

-

1

+

A\$1,072⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	A\$1,072.00 each
Qty 5+	A\$1,019.84 each
Need More?	Request Quote

Product Downloads

Physical & Mechanical Properties	
1, 2, 3, 4, 5, 10, 15, 20, 30, 40, 50	Pattern Size (mm):
76.2 x 76.2	Dimensions (mm):
1.50	Thickness (mm):
±0.001	Line Width Tolerance (mm):

Optical Properties	
Coating:	Vacuum Deposited Chromium Oxide (specular reflectivity <5% @ 550nm)
Substrate:	Float Glass
Surface Quality:	20-10
Surface Flatness (P-V):	λ/mm

Regulatory Compliance	
RoHS 2015:	Compliant
Certificate of Conformance:	View
Reach 240:	Compliant

Product Details

- For Calibration of Measurement Software
- NIST Traceable Certificate of Accuracy Included
- 1mm to 50mm Squares

Concentric Square Targets provide an accurate means of calibrating measurement software for image processing. The squares vary in dimensions to accommodate different fields of view. The square targets are NIST Traceable Certificate of Accuracy included. Concentric Square Targets are offered in 1 to 50mm pattern sizes. Included in the packaging is a serialized NIST Traceable Certificate of Accuracy per ML-STD-45662A