

# Iris Mount for 24mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock **#23-124** 20+ In Stock

-

1

+

A\$81<sup>60</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-4        | A\$81.60 each                 |
| Qty 5-9        | A\$73.60 each                 |
| Qty 10-25      | A\$66.40 each                 |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

| Physical & Mechanical Properties |                                |
|----------------------------------|--------------------------------|
| 24.0                             | Compatible Iris Diameter (mm): |
| 39.0                             | Outer Diameter (mm):           |
| 6.00                             | Thickness (mm):                |

|       |                           |
|-------|---------------------------|
| 19.05 | Optical Axis Height (mm): |
|-------|---------------------------|

Threading & Mounting

|                  |                   |
|------------------|-------------------|
| M4 x0.7 and 8-32 | Mounting Threads: |
| 4-40             | Set Screw Thread: |

Regulatory Compliance


|           |                             |
|-----------|-----------------------------|
| Compliant | RoHS 2015:                  |
| View      | Certificate of Conformance: |
| Compliant | Reach 235:                  |

Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

Technical Information

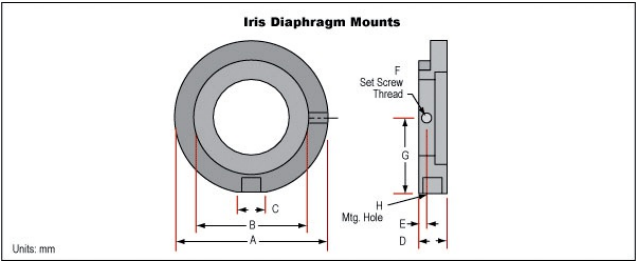

| Iris Diameter | A    | B    | C    | D    | E   | F    | G    | H      | Stock No.               |
|---------------|------|------|------|------|-----|------|------|--------|-------------------------|
| 19.8          | 30.8 | 19.8 | 6.1  | 6.35 | 2.5 | 4-40 | 15.1 | 8-32   | <a href="#">#53-918</a> |
| 37.0          | 50.8 | 37.0 | 9.0  | 9.5  | 2.8 | 6-32 | 25.0 | 1/4-20 | <a href="#">#53-919</a> |
| 53.0          | 66.0 | 53.0 | 9.9  | 9.5  | 3.0 | 6-32 | 32.7 | 1/4-20 | <a href="#">#53-920</a> |
| 70.0          | 86.0 | 70.0 | 10.1 | 9.5  | 3.8 | 6-32 | 42.7 | 1/4-20 | <a href="#">#53-921</a> |
| 21.0          | 32.0 | 21.0 | 6.2  | 9.5  | 3.2 | 4-40 | 15.7 | 8-32   | <a href="#">#54-862</a> |
| 38.0          | 52.0 | 38.0 | 9.1  | 9.5  | 3.2 | 6-32 | 25.6 | 1/4-20 | <a href="#">#54-863</a> |
| 54.0          | 67.0 | 54.0 | 8.9  | 9.5  | 3.8 | 6-32 | 33.2 | 1/4-20 | <a href="#">#54-864</a> |
| 72.0          | 88.0 | 72.0 | 10.3 | 11.5 | 3.8 | 6-32 | 43.7 | 1/4-20 | <a href="#">#54-865</a> |

