


Linear Variable Shortpass Filter

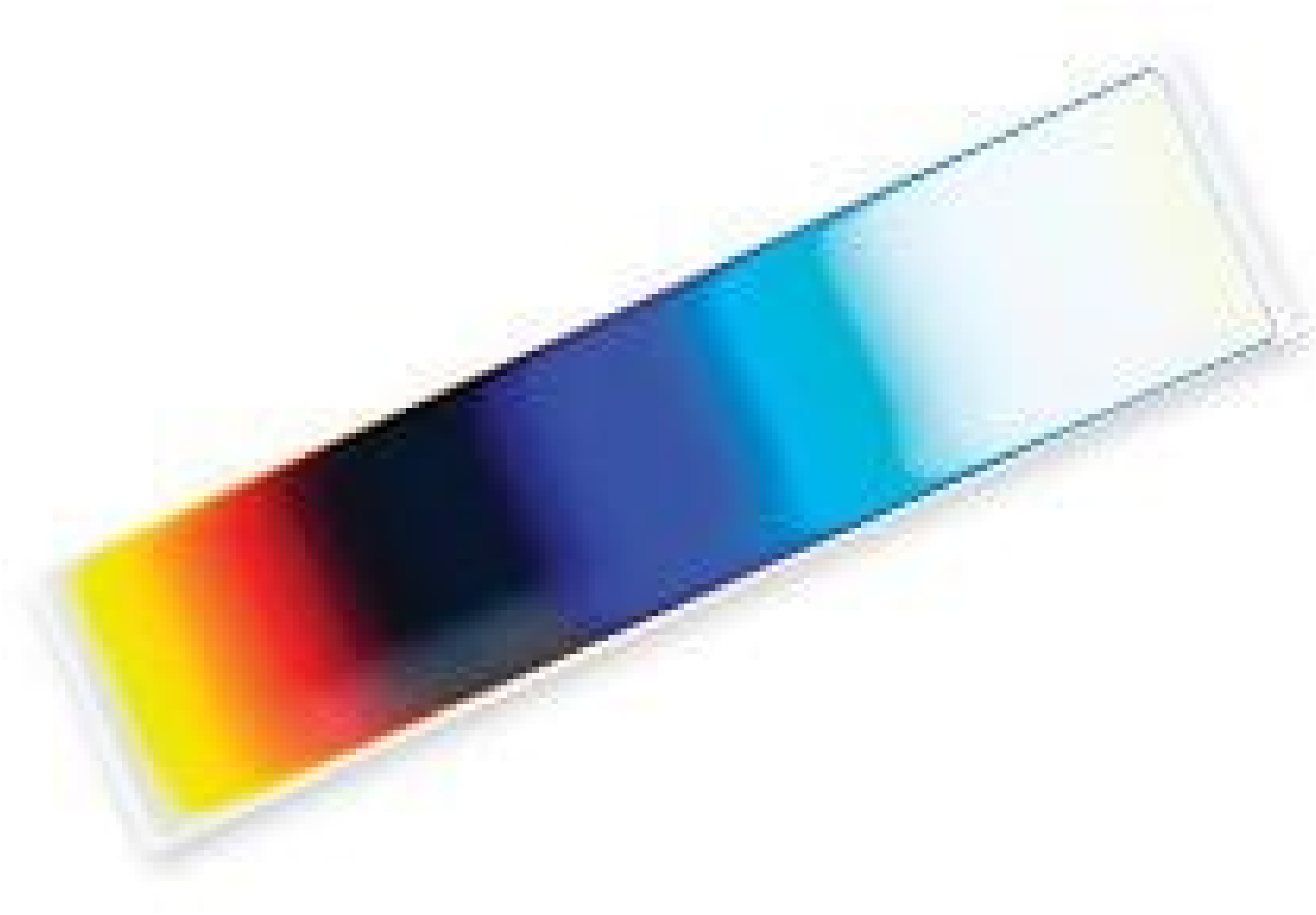

Stock **#83-983** 3-5 DAYS

- 1 + **A\$2,568.00**

ADD TO CART

Qty 1-9
A\$2,568.00
Qty 10+
A\$2,304.00
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm):
60.0 x 15.0

Optical Density OD (Average):
≥3.0

Substrate: ☐
[Fused Silica](#) (Coming 7980)

Length (mm):
60.00

Coating: Variable
Optical Density Steps: Edge: 340 - 420nm, >3.0 to 725nm Edge: 420 - 500nm, >3.0 to 850nm Edge: 500 - 850nm, >3.0 to 860nm
Thickness (mm): 3.00
Transmission (%): >70
Type: Shortpass Filter
Width (mm): 15.00
Transmission Steps (%): Edge: 340 - 420nm, >70% over 20nm Edge: 420 - 500nm, >85% over 40nm Edge: 500 - 850nm, >92% over 40nm
Aperture (mm): 0.2 x 8.0
Slope Factor (%): 1.6
Linear Dispersion (%): 0.57
Wavelength Range (nm): 340 - 850

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View
