


OD 0.04 - 1.0, 50.8 x 25.4mm Stepped ND Filter

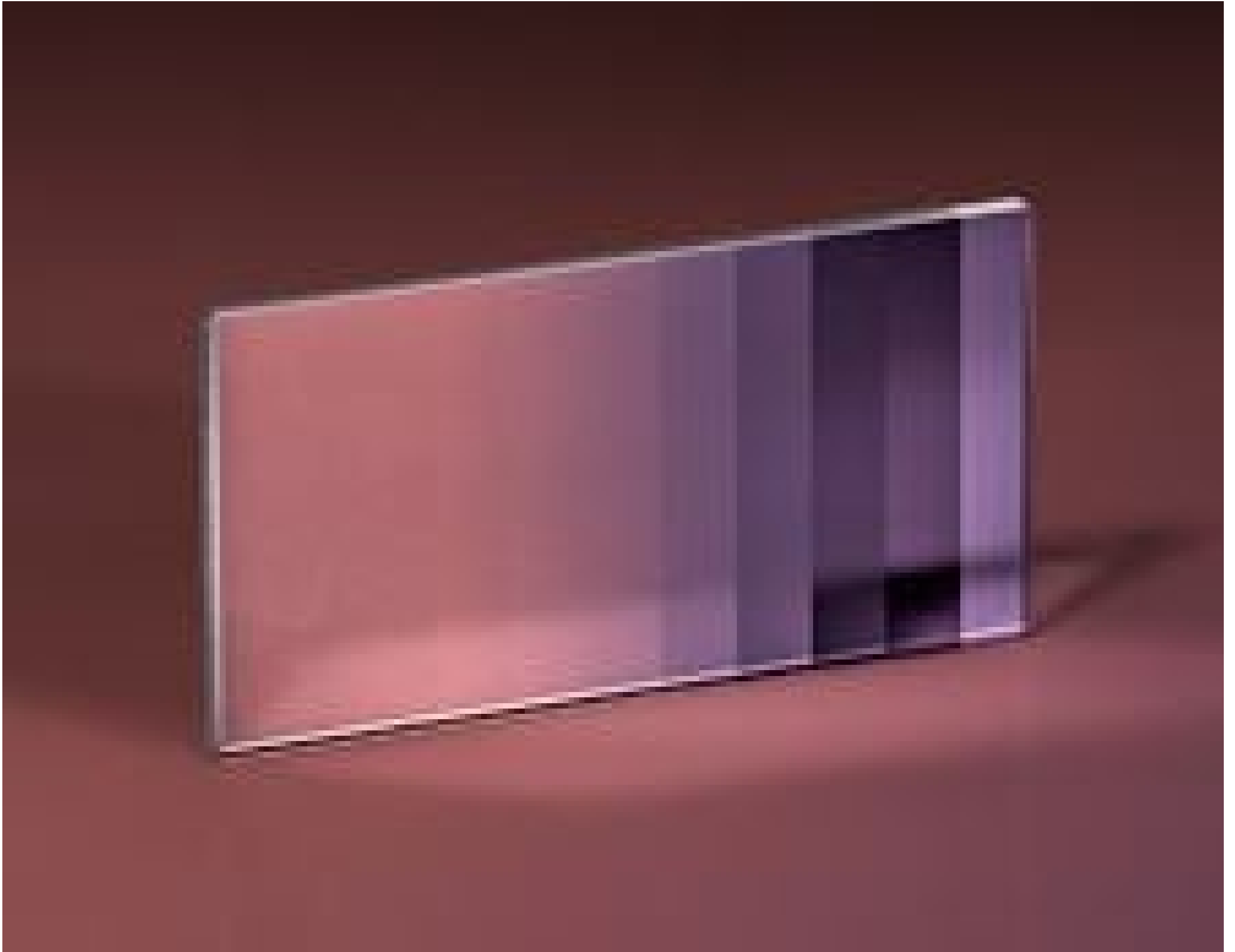

Stock #32-599 **1 In Stock**

- 1 + A\$344.⁰⁰

ADD TO CART

Volume Pricing

| | |
|------------|-------------------------------|
| Qty 1-10 | A\$344.00 each |
| Qty 11-25 | A\$310.40 each |
| Qty 26-49 | A\$296.00 each |
| Need More? | Request Quote |

Product Downloads

General

Neutral Density Filter **Type:**

Physical & Mechanical Properties

25.4 x 50.8 **Dimensions (mm):**

2.0 **Length (inches):**

50.80 Length (mm):

0.062 Thickness (inches):

1.0 Width (inches):

25.40 Width (mm):

Optical Properties

0.04 - 1.0 Optical Density OD (Average):

Float Glass Substrate:

Stepped Variable Coating:

400 - 700 Blocking Wavelength Range (nm):

Regulatory Compliance

Compliant Reach 181:

Compliant RoHS 2015:


View Certificate of Conformance:

Product Details

- 11 Discrete Density Steps
- Design Wavelength of 400 - 700nm
- Density Neutrality of $\pm 5\%$

Density and transmission vary in eleven equal steps across the surface length. The steps are abrupt changes and no light escapes between them. Spectrally flat neutral density coating. Ideal for applications requiring variable densities and known density values.

Technical Information

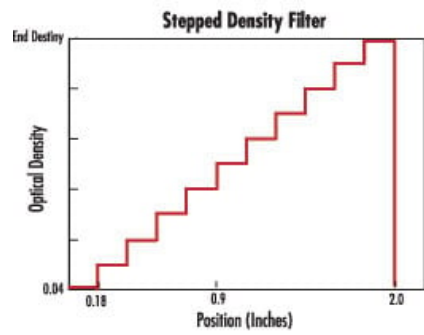

Compatible Mounts