


OD 0.04 - 1.0, 76.2 x 25.4mm, Continuously Variable ND Filter

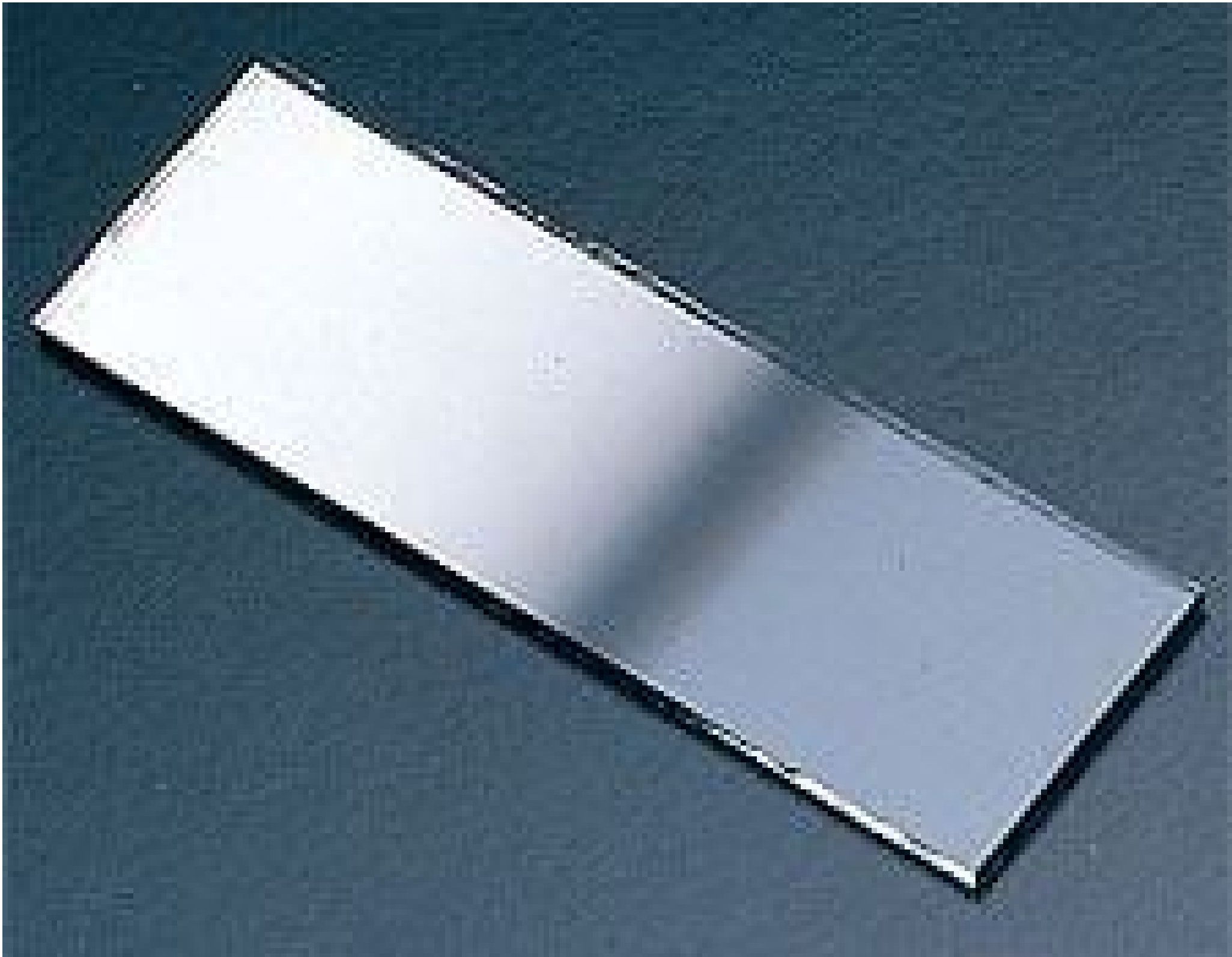

Stock #64-381 3-5 DAYS

- 1 + **A\$155.20**

ADD TO CART

Qty 1-10
A\$155.20
Qty 11+
A\$139.68
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm): 25.4 x 76.2
Angle of Incidence (°): 0.00
Optical Density OD (Average): 0.04 - 1.0

Substrate: ☐ Float Glass
Length (inches): 3.00
Length (mm): 76.20
Coating: Surface 1: Inconel
Thickness (inches): 0.063 ±0.01
Thickness (mm): 1.60 ±0.25
Type: Neutral Density Filter
Width (inches): 1.00
Width (mm): 25.40
Blocking Wavelength Range (nm): 400 - 700
Construction: Plate

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View