


OD 0.04 - 3.0, 50.8 x 25.4mm Stepped ND Filter

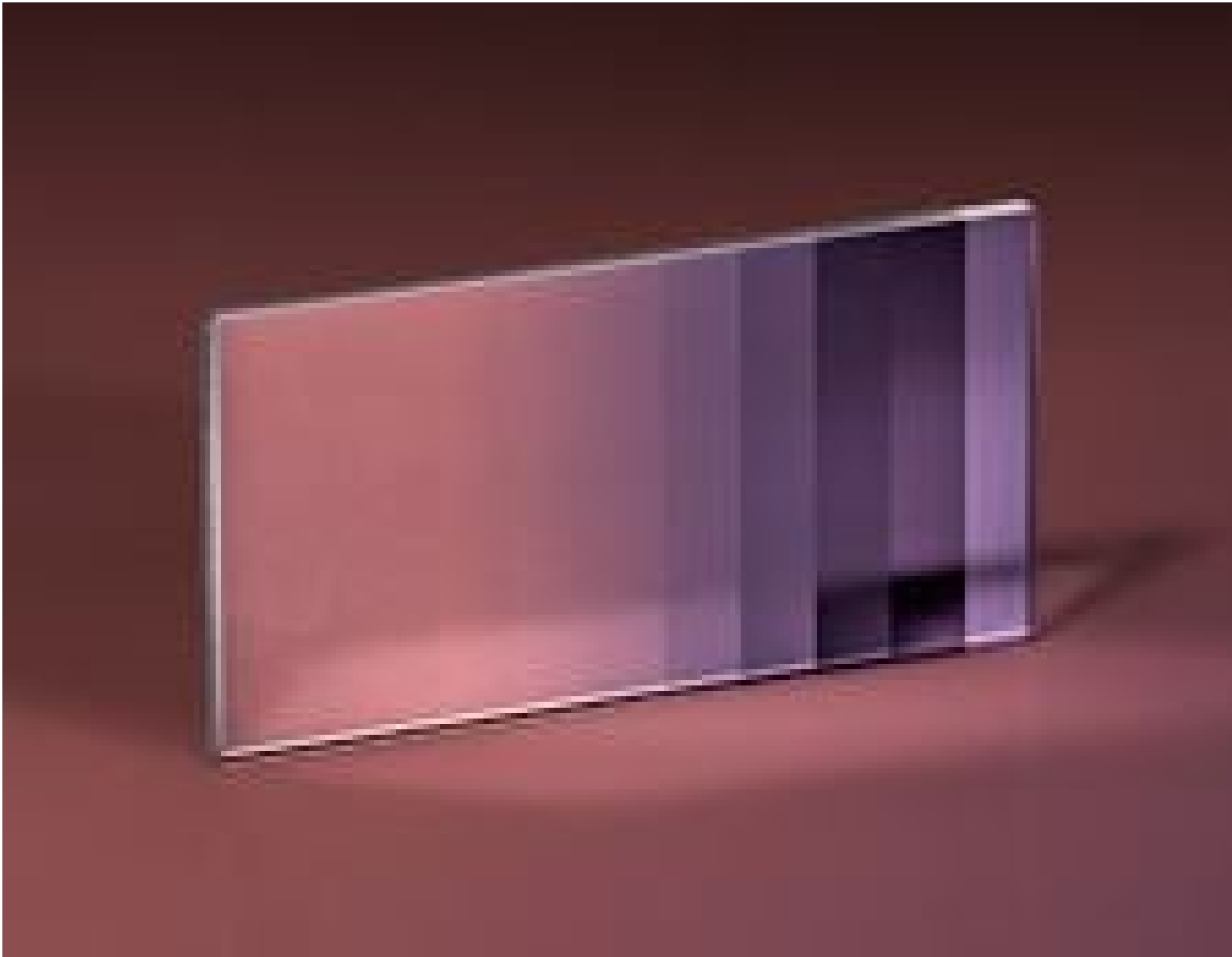

Stock **#64-384** 3-5 DAYS

-

1

+

A\$364.80

ADD TO CART

Qty 1-10
A\$364.80
Qty 11+
A\$310.08
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm):
25.4 x 50.8

Optical Density OD (Average):
0.04 - 3.0

Substrate: ☐
Float Glass

Length (inches):
2.0

Length (mm): 50.80
Coating: Stepped Variable
Thickness (inches): 0.062
Type: Neutral Density Filter
Width (inches): 1.0
Width (mm): 25.40
Blocking Wavelength Range (nm): 400 - 700

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View