


Reflected (0.1875 - 12 lp/mm), Sinusoidal Target

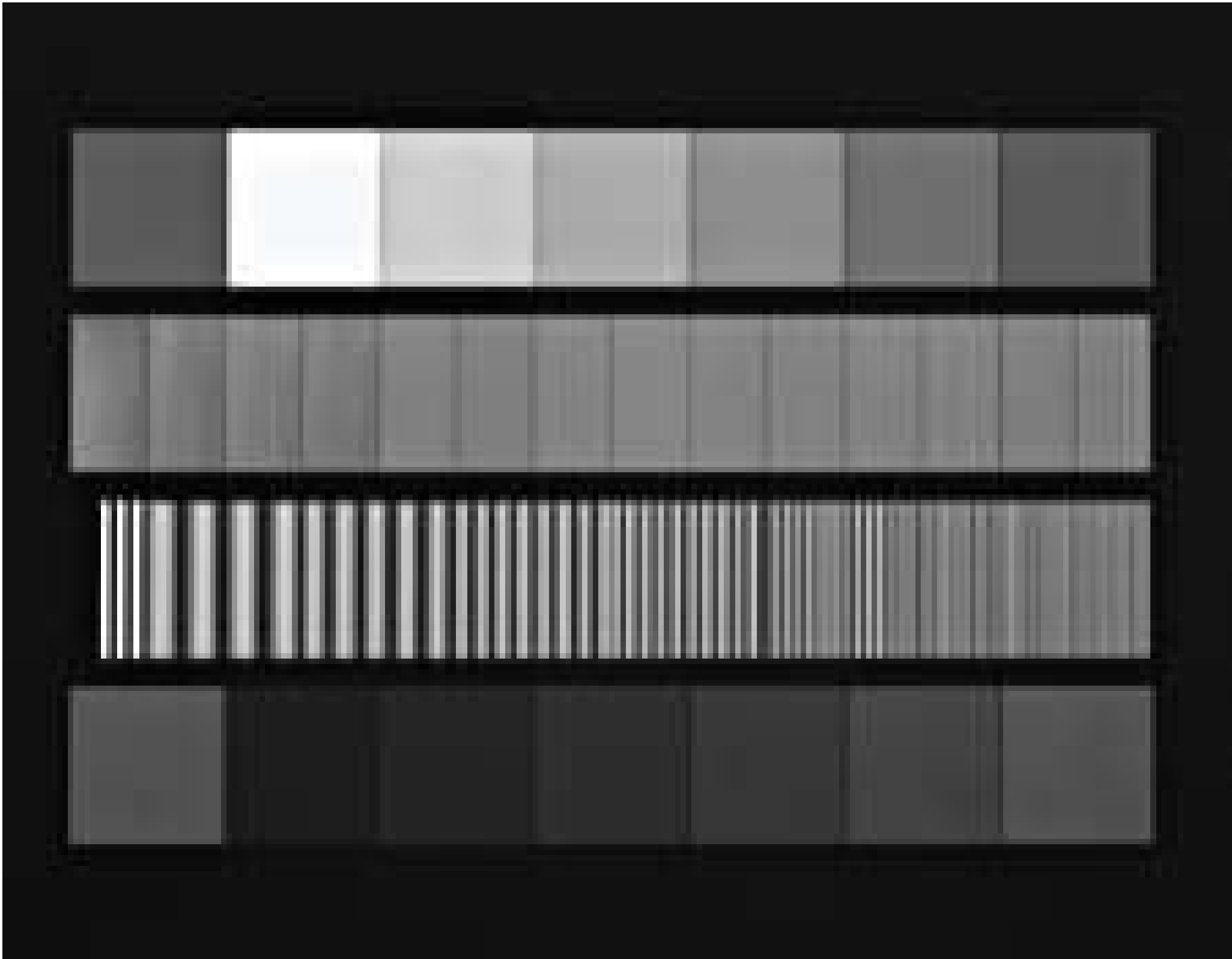

Stock #54-804 3-5 DAYS

1

A\$1,774.40

ADD TO CART

Qty 1-4
A\$1,774.40
Qty 5+
A\$1,686.40
Volume Pricing
Request Quote

Get Product Downloads

Frequency (lp/mm):
0.1875 - 12

Substrate:
Float Glass

Optical Density OD (Average):
Grayscale Pattern: 0.2 - 1.2, ±0.02

Pattern Size (mm):
70 x 48

Dimensions (mm): 85 x 200 ±nominal
Thickness (mm): 0.18 ±nominal
Type: Reflected Sinusoidal
Construction: Semi-Matte, High Grain, Quality Photographic Paper
Harmonic Distortion (%): <3
NIST Certification: No
Modulation: 60%

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant