


Replacement Unmounted Window for 800nm, 0.80 NA, aplanoXX Aplan Objective

See More by [AdlOptica](#)

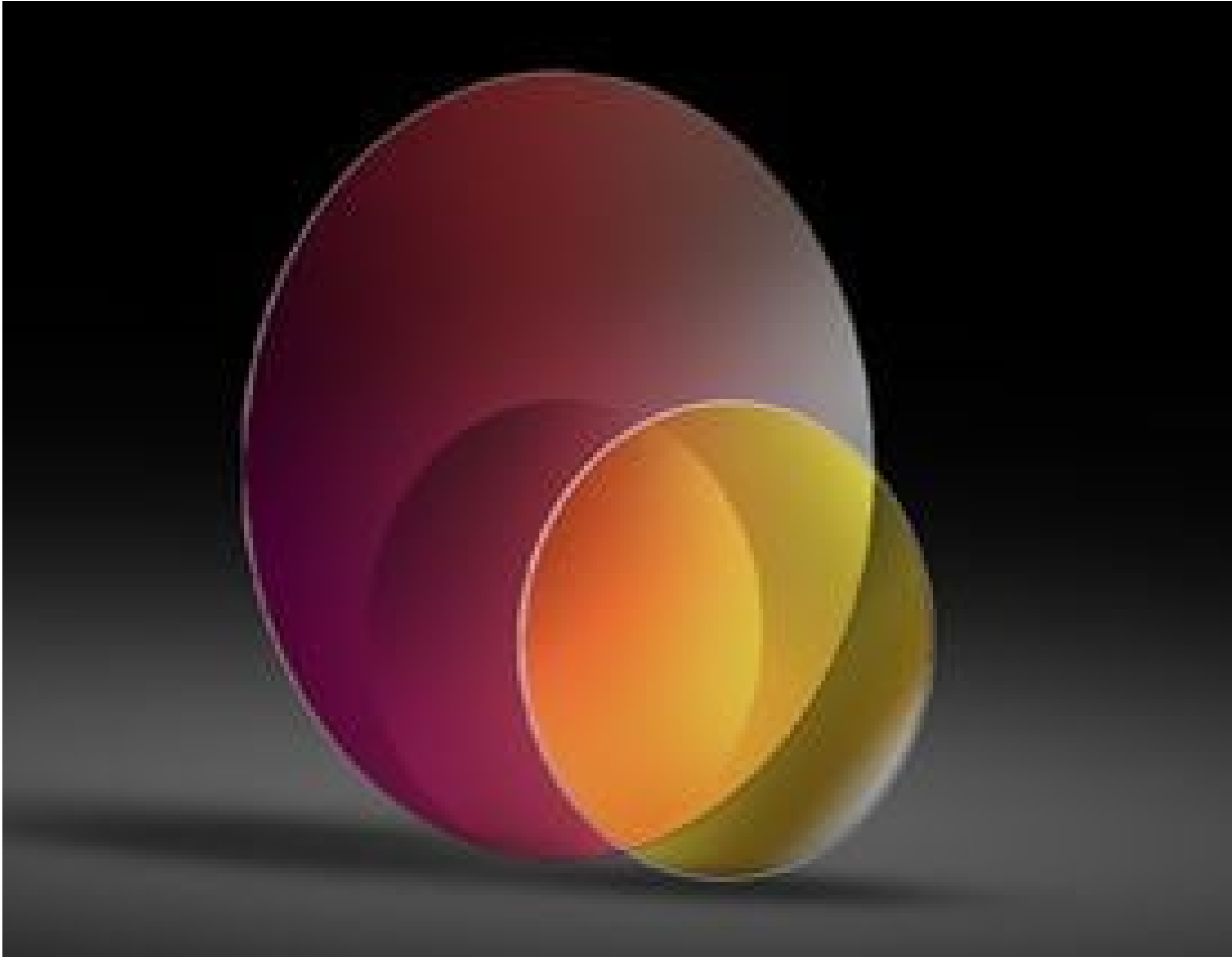

Replacement Window

Stock **#19-494** 3-5 DAYS

- 1 + **A\$155.20**

ADD TO CART

Qty 1+

A\$155.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Clear Aperture CA (mm):
8

Design Wavelength DWL (nm):
800

Diameter (mm):
12.00

Model Number:
Protective Window_D12_800

Type:

Protective Window
Note: Protective window for #19-492 , #19-496
Wavelength Range (nm): 770 - 900
Damage Threshold, By Design: ☐ 25 mJ @ 5ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant