 



SCHOTT BG40, 12.5mm Dia., 2mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

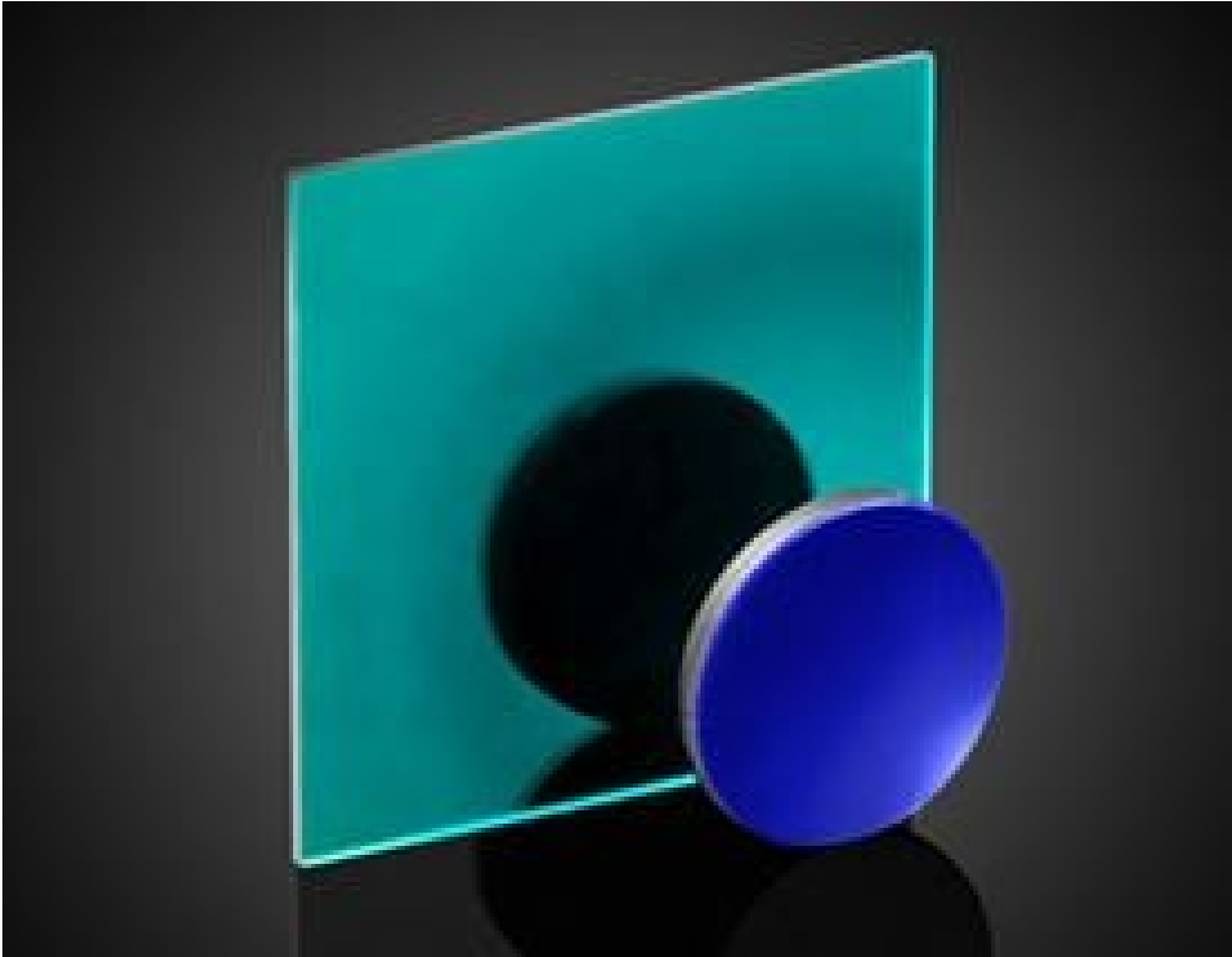

Stock #16-383 3-5 DAYS

[Additional Bandwidths](#)

- 1 +

A\$65.60

ADD TO CART

Qty 1-10	A\$65.60
Qty 11+	A\$59.20
Volume Pricing	Request Quote

Get Product Downloads
Diameter (mm): 12.50
Center Wavelength CWL (nm): 514.00

Density (g/cm³): 2.74
Glass/Filter Number: SCHOTT BG40
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.53
Surface Quality: 60-40
Transformation Temperature (°C): 313
Thickness (mm): 2.00 ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--