


# SCHOTT NG11, 0.1 OD, 12.5mm Dia., Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

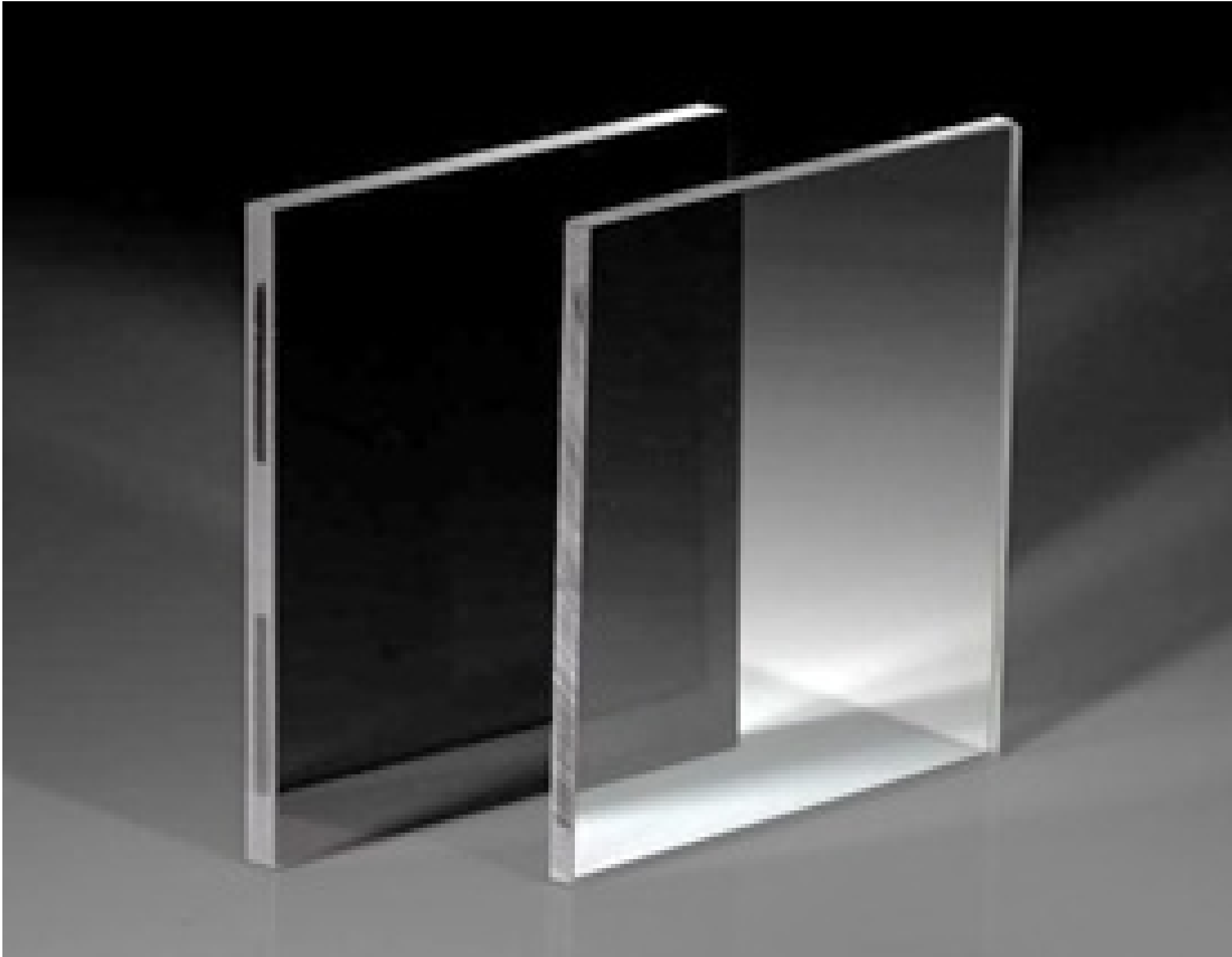

Stock #16-717 3-5 DAYS



1



A\$41.60

ADD TO CART

Qty 1-10

A\$41.60

Qty 11+

A\$36.80

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):  
12.50

Optical Density OD (Average):  
0.1 ±0.006 @ 546nm

Glass/Filter Number:  
[SCHOTT NG11](#)

Coating:

|                                                      |
|------------------------------------------------------|
| Uncoated                                             |
| <b>Index of Refraction <math>n_d</math>:</b><br>1.50 |
| <b>Surface Quality:</b><br>80-50                     |
| <b>Transformation Temperature (°C):</b><br>481       |
| <b>Thickness (mm):</b><br>0.60                       |
| <b>Thickness Tolerance (mm):</b><br>(nominal)        |
| <b>Transmission (%):</b><br>79.43 ±1.03% @ 546nm     |
| <b>Type:</b><br>Neutral Density Filter               |
| <b>Dimensional Tolerance (mm):</b><br>±0.38          |
| <b>Wavelength Range (nm):</b><br>400 - 700           |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS:</b><br><a href="#">Compliant</a>                  |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 240:</b><br><a href="#">Compliant</a>             |