


SCHOTT NG4, 0.6 OD, 12.5mm Dia., Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

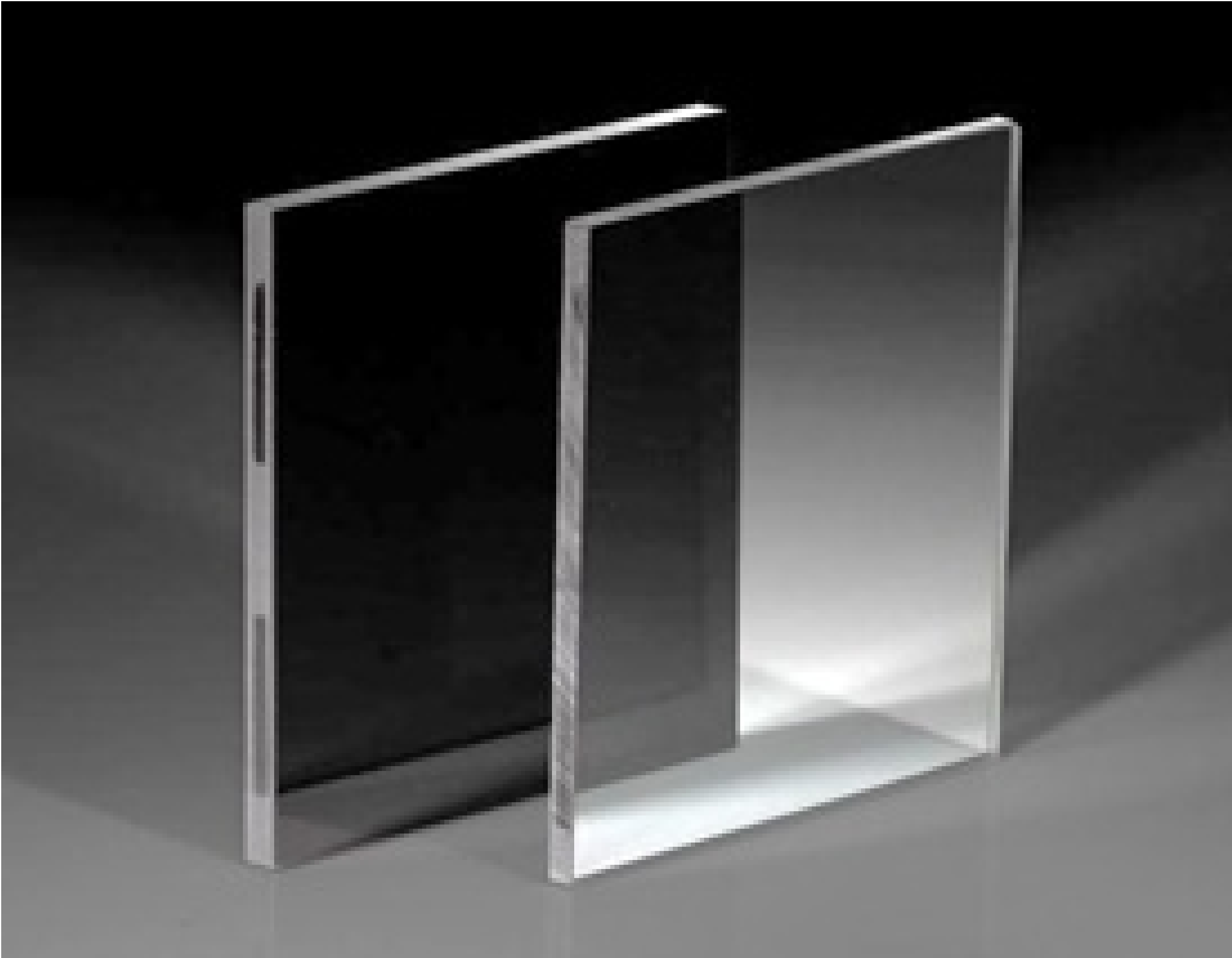

Stock **#16-647** 3-5 DAYS

- 1 +

A\$41.60

ADD TO CART

Qty 1-10

A\$41.60

Qty 11+

A\$36.80

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
12.50

Optical Density OD (Average):
0.6 ±0.03 @ 546nm

Glass/Filter Number:
[SCHOTT NG4](#)

Coating:

Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 483
Thickness (mm): 1.10
Thickness Tolerance (mm): (nominal)
Transmission (%): 25.12 ±1.51% @ 546nm
Type: Neutral Density Filter
Dimensional Tolerance (mm): ±0.38
Wavelength Range (nm): 400 - 700

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant