


SCHOTT NG4, 1.0 OD, 50mm Sq., Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

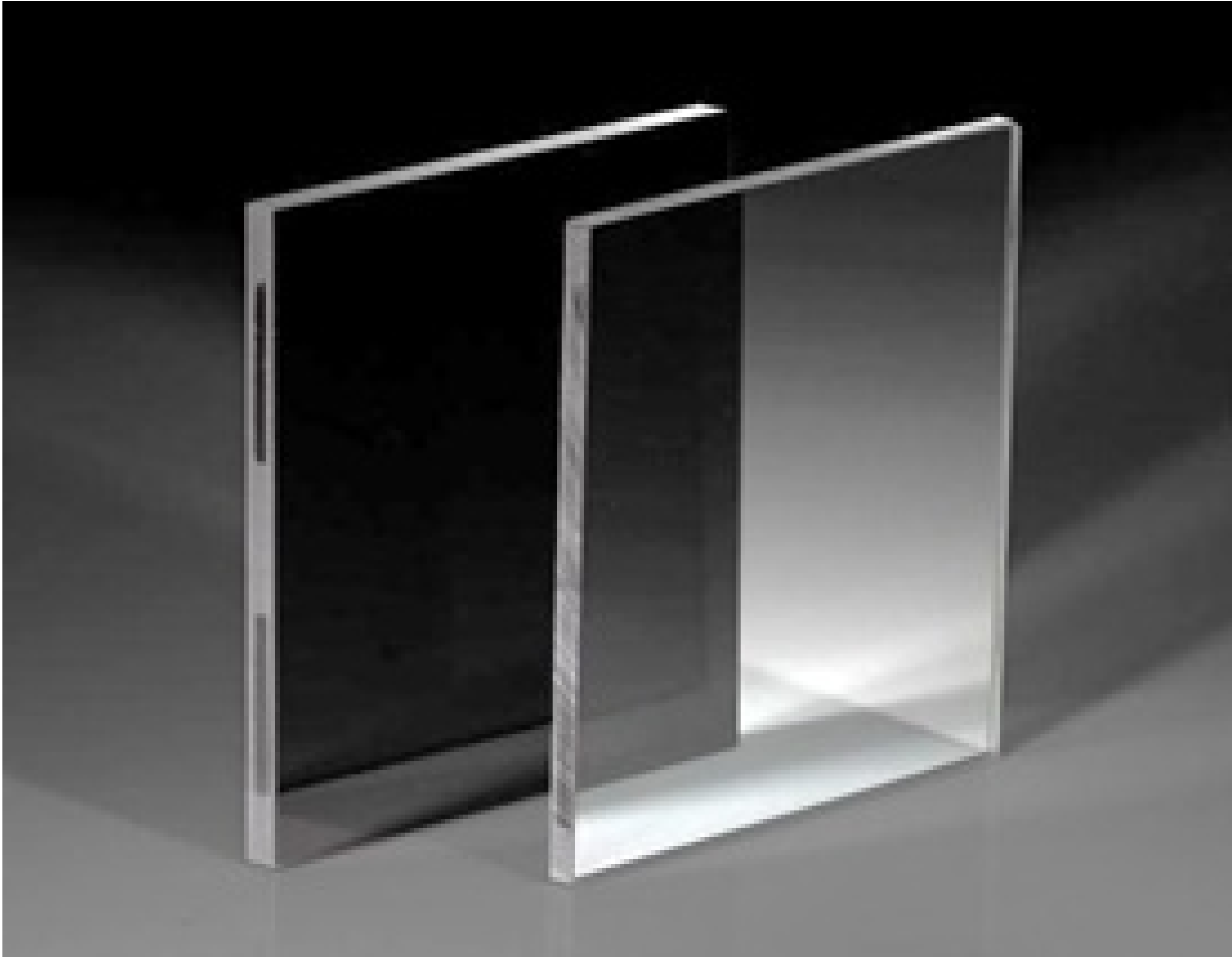

Stock #14-048 3-5 DAYS

-

1

+

A\$148.80

ADD TO CART

Qty 1-10

A\$148.80

Qty 11+

A\$131.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Optical Density OD (Average):
1.0 ±0.03 @ 546nm

Glass/Filter Number:
[SCHOTT NG4](#)

Length (mm):

50.00
Coating: Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 60-40
Transformation Temperature (°C): 483
Thickness (mm): 1.90
Thickness Tolerance (mm): (nominal)
Transmission (%): 10.00 ±0.6% @ 546nm
Type: Neutral Density Filter
Width (mm): 50.00
Parallelism (arcmin): ≤3
Dimensional Tolerance (mm): ±0.2
Wavelength Range (nm): 400 - 700

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant