

[See all 2 Products in Family](#)

5.0 - 100.0mm Optic Dia., Self-Centering Jaw Clamp



Self-Centering Jaw Clamps

Stock **#16-078** 11 In Stock

-

1

+

A\$656⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	A\$656.00 each
Qty 5+	A\$578.88 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

General

- Type:
- Fixed
- Type of Optics:
- Circular

Physical & Mechanical Properties

166	Height (mm):
138	Outer Diameter (mm):
0.68	Weight (lbs):
Black Anodized Aluminum	Construction:

Threading & Mounting

5.0 - 100.0	Size of Compatible Optics (mm):
M6 x 1.0, ¼-20	Compatible Post:

Regulatory Compliance

Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

PRODUCT DETAILS


• Two Mount Sizes Available, for 4mm-36mm and 5mm-100mm Dia. Optics

• Optical Centerline Remains Constant Regardless of Optical Diameter

• Mounts Feature Both Metric and English Tapped Mounting Holes

Self-Centering Jaw Clamps are ideal for easily interchanging optics of different diameters in a system while maintaining a constant optical centerline of the system. Mounts are available for either mounting 4mm to 36mm diameter optics ([#16-077](#)) or 5mm to 100mm diameter optics ([#16-078](#)). The small jaw clamp features both M4 x0.7 and 8-32 tapped mounting holes, while the large jaw clamp features both M6 x 1.0 and ¼"-20 tapped mounting holes. The stainless-steel tipped jaws feature a v-groove to help vertical alignment of thinner optics. Self-Centering Jaw Clamps are directly mountable to [TECHSPEC® Stainless Steel Mounting Posts](#) and [Pedestal Posts](#).

TECHNICAL INFORMATION

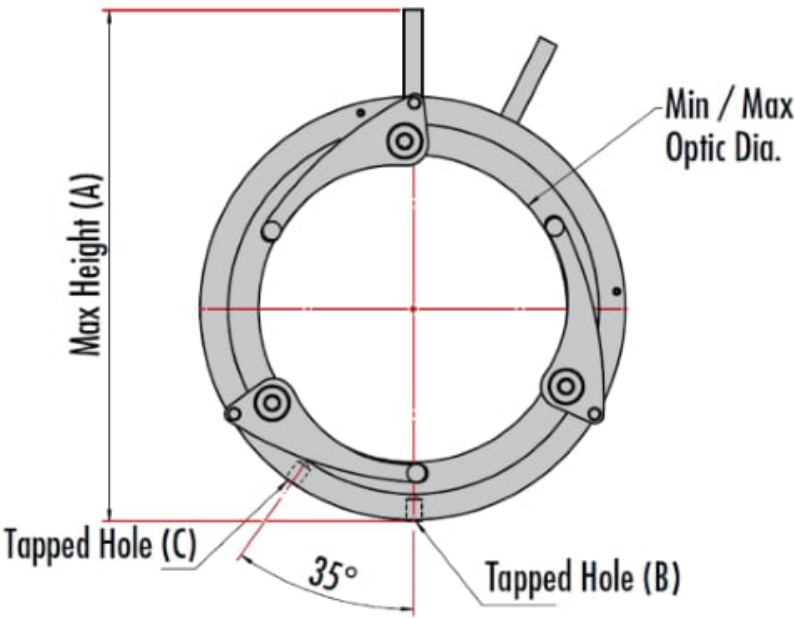

Outer Diameter (mm)	Min. Optic Diameter (mm)	Max. Optic Diameter (mm)	A (mm)	B	C	Stock No.
58	4	36	74	#8-32	M4 x0.7	#16-077
138	5	100	166	¼-20	M6 x 1.0	#16-078