


Transmitted (0.375 to 80 lp/mm), Sinusoidal Target

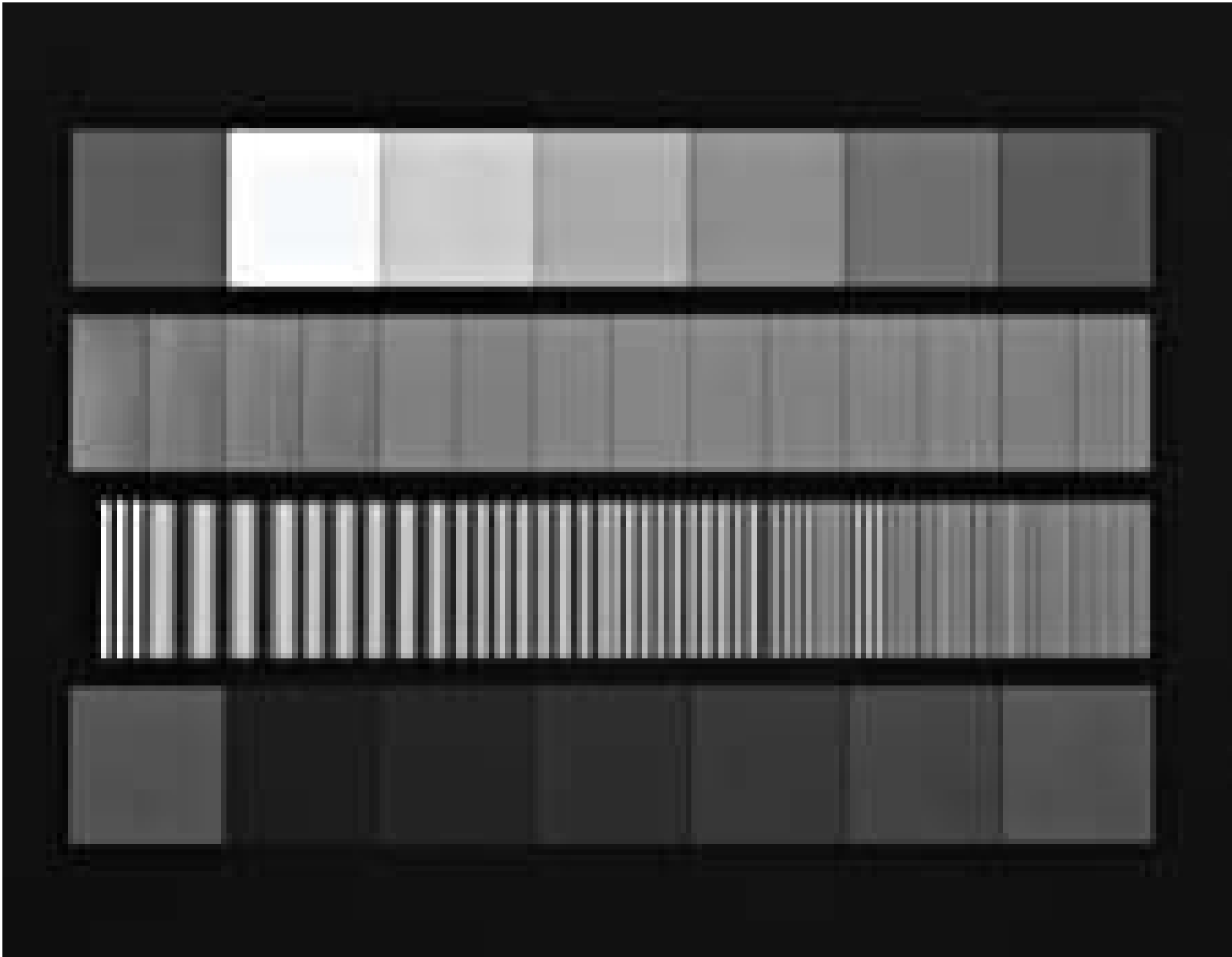

Stock #54-803 3-5 DAYS

- 1 + **A\$3,171.20**

ADD TO CART

Qty 1-4
A\$3,171.20
Qty 5+
A\$3,012.96
Volume Pricing
Request Quote

Get Product Downloads

Frequency (lp/mm):
0.375 - 80

Substrate:
Float Glass

Optical Density OD (Average):
Grayscale Pattern: 0.2 - 1.2, ±0.02

Pattern Size (mm):
70 x 46

Dimensions (mm): 70 x 102 ±nominal
Surface Quality: 60-40
Thickness (mm): 2.00 ±nominal
Type: Transmitted Sinusoidal
Construction: High Resolution Film Sandwiched in Float Glass
Harmonic Distortion (%): <3
NIST Certification: No
Modulation: 80%

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant