


TECHSPEC® Two Knob Stage Only

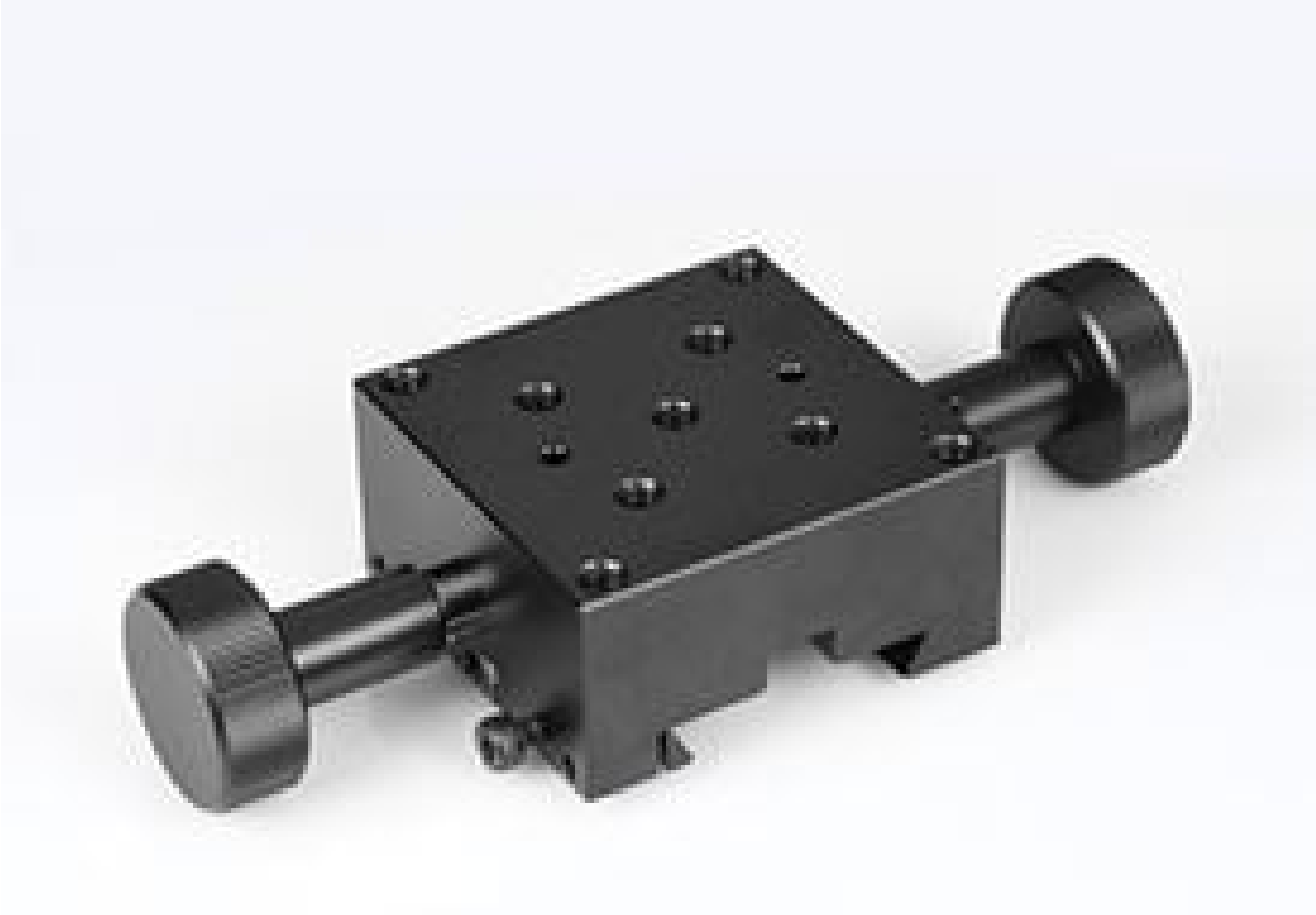

#59-332

Stock #59-332 3-5 DAYS

- 1 +

A\$246.40

ADD TO CART

Qty 1+

A\$246.40

Volume Pricing

[Request Quote](#)

Get Product Downloads

Type of Movement:
Linear (X)

Type of Drive:
Rack and Pinion

Type:
English

Stage Size (mm):
62 x 60

Construction:
Black Anodized Aluminum

Graduation (inches): 0.1 (Vernier)
Load Capacity, Normal (kg): 5
Load Capacity, Vertical (kg): 2
Mounting Threads: (9) 1/4-20
Note: Two Knob Carrier
S.H.C.S. C'bore: N/A
Travel Per Knob Rotation (inches): 0.71

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Contains SVHC(s)
Certificate of Conformance: View