

VZM™ 300i Zoom Imaging Lens



VZM™ 200i



Stock #52-571

2 In Stock

-

1

+

A\$2,256⁰⁰

+7

ADD TO CART

Volume Pricing	
Qty 1+	A\$2,256.00 each
Need More?	Request Quote

Product Downloads

General

Type:

High Magnification Zoom Lens

Physical & Mechanical Properties

Length excluding Threads (mm):

151.70

Maximum Diameter (mm):

30.00


232.00	Weight (g):
Optical Properties	
11.4 - 2.8mm	Horizontal Field of View, 2/3" Sensor:
8.0 - 2.0mm	Horizontal Field of View, 1/2" Sensor:
±3	Working Distance Tolerance (mm):
37.5 - 111 lp/mm	Resolution, Object Space:
50 - 37 lp/mm	Resolution, Image Space:
4:1	Zoom Ratio:
0.75X- 3X	Primary Magnification PMAG:
56.00	Working Distance (mm):
VIS	Lens Wavelength Range:
Sensor	
2/3"	Maximum Sensor Format:
Threading & Mounting	
M22.5 x0.50	Filter Thread:
C-Mount	Mount:
Regulatory Compliance	
View	Certificate of Conformance:

Product Details

- Designed to Accomodate up to 2/3" Sensor Size Formats
- Dependable, Versatile Performance in Compact Designs
- Analog and Digital [Imaging Systems](#) Available

VZM™ Zoom Imaging Lenses enable inspection of a wide range of objects without the inconvenience of changing working distances. In addition, the parfocal zoom allows magnifications to be easily changed without refocusing. These economical lenses are available in working distances ranging from 35mm to 175mm and offer a maximum 2/3" sensor format. Iris versions (i-series) all have locking iris, front filter thread, removable mounting flange, and optional zoom lock. All lenses have a 50mm diameter flange (removable on iris versions except 450i Right Angle) for mounting. VZM™ Zoom Imaging Lenses are ideal for inspection of integrated circuits and solder joints. Also suited for quality control and laboratory inspection needs, as well as surface analysis.

Technical Information

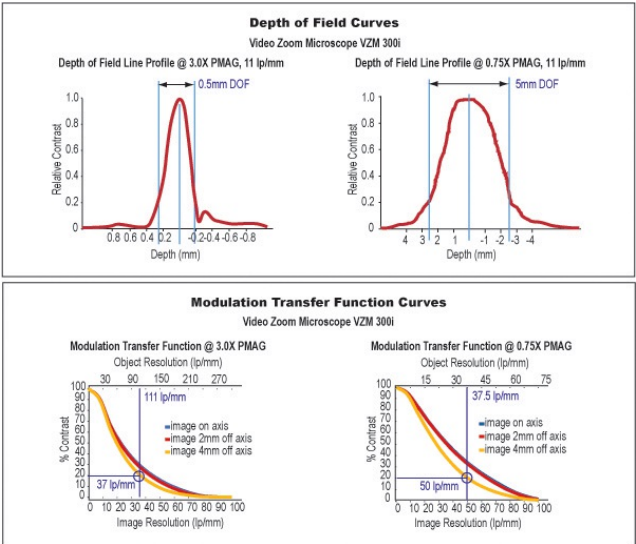

VZM Model	100i	200i	300	300i	450	450i	600i	1000	1000i
Zoom Ratio	4:1	4:1	4:1	4:1	6.4:1	6:1	6:1	4:1	4:1
Magnification	0.25 - 1X	0.5 - 2X	0.75 - 3X	0.75 - 3X	0.7 - 4.5X	0.75 - 4.5X	1 - 6X	2.5 - 10X	2.5 - 10X
Manual Iris	☐	☐		☐		☐	☐		☐
Rotatable Mount	☐	☐		☐		☐	☐		☐
Zoom Lock Adapter	☐	☐		☐		☐	☐		☐

